

## Long Barrel Copper Lug T&B Catalog Number:

54820BE

**UPC Number:**


78621019473

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 350 kcmil Wire, 1/4" Bolt Size, 3/4" Hole Spacing, Tin Plated Blind End, Red 71

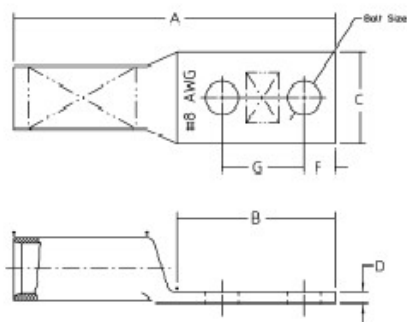

### General

Material	Copper
Finish	Tin Plated
Wire Size	350 kcmil
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Red
Die Code	71

### Dimension Information

A (inches)	4.125
B (inches)	1.906
C (inches)	1.359
D (inches)	.172
E (inches)	.922
F (inches)	.25
G (inches)	0.75

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	42 lbs. per 100

### Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

8155 T&B Blvd.  
Memphis, TN 38125

Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)