

## Long Barrel Copper Lug T&B Catalog Number:

256-30695-593

**UPC Number:**


78621007140

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 1/0 AWG Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Pink 42

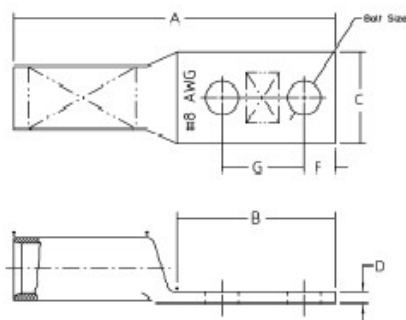

### General

Material	Copper
Finish	Tin Plated
Wire Size	1/0 AWG
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Pink
Die Code	42

### Dimension Information

A (inches)	4.281
B (inches)	2.875
C (inches)	.75
D (inches)	.125
E (inches)	.531
F (inches)	.625
G (inches)	1.75

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Order Multiple	5
T&B Inner Pack	5
Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	10.88 lbs. per 100

### Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)