

Long Barrel Aluminum Lug T&B Catalog Number:

60278

UPC Number:


78621060278

Status:

Active

Description:

Aluminum Two-Hole Lug - Straight Long Barrel - max 35KV, 750 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Yellow 115H

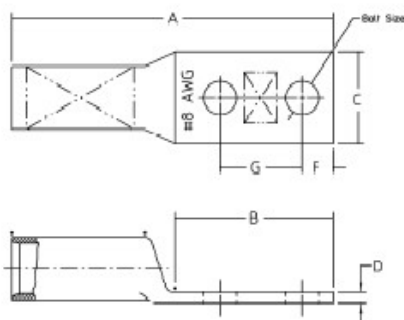

General

Material	Aluminum
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	115H

Dimension Information

A (inches)	7.15
B (inches)	3
C (inches)	2.13
D (inches)	.4
E (inches)	1.5
F (inches)	.5
G (inches)	1.75

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	1
T&B Inner Pack	1
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	60 lbs. per 100

Application Support

T&B Sales Drawings	wsd-000581
T&B Instruction Sheets	ta00880-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

UL listed for 750 code and 900 compact Aluminum conductor.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com