



Locking Fork Terminal T&B Catalog Number:

UPC Number:
Status:
Description:

RC2207-250
78621082043
Active

Expanded Insulated Vinyl Locking Fork Terminal For Wire Range 12-10
Stud Size #6, Yellow


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Locking fork terminals have a specially designed tongue that lets them go on like a fork and stay on like a ring.

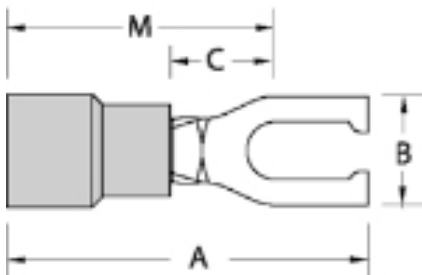

General

Insulation Type	Expanded Insulated Vinyl
Terminal Series	RC
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	12-10
Stud Size	#6

Dimension Information

Maximum Insulation (inches)	.250
Stock Thickness	.04
A (inches)	1.07
B (inches)	.31
C (inches)	.27
M (inches)	.91

Specifications

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	ERG4001, ERG4003, WT145C, WT2000, WT112M, WT145C
Recommended Tool	ERG4001

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	0.44 lbs. per 100
Alternate Package Qty	10RC-6FLX

Application Support

T&B Instruction Sheets	
Overview	Available on Website

Wire Guide Tables

Available on Website

Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

Certifications

RoHS Compliance

Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com