

**Long Barrel Copper Lug**  
**T&B Catalog Number:**

54872BE

**UPC Number:**


78621089807

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 350 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Red 71

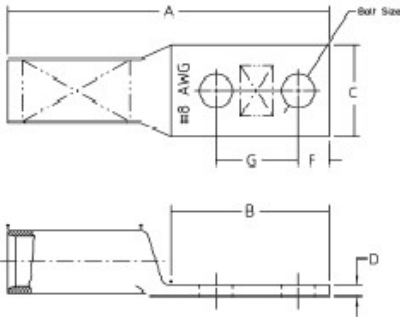

**General**

Material	Copper
Finish	Tin Plated
Wire Size	350 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Red
Die Code	71

**Dimension Information**

A (inches)	5.344
B (inches)	2.984
C (inches)	1.359
D (inches)	.172
E (inches)	.922
F (inches)	.5
G (inches)	1.75

**Tooling**

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

**Packaging**

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	41.88 lbs. per 100

**Application Support**

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

**Notes**

Dimensions given for reference only. Dimensions may vary up to .030.

**Certifications**

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)