



Pin Terminals
T&B Catalog Number:

10RC-55PT

UPC Number:

78621092176

Status:

Active

Description:

Insulated Vinyl Pin Terminals For Wire Range 12-10 Length 1.06 Diameter .11


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Provides an easy and effective way to terminate stranded wire into European/metric-style terminal blocks.

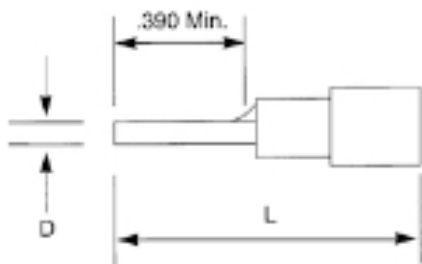

General

| | |
|-----------------|---------------------|
| Insulation Type | Insulated Vinyl |
| Terminal Series | RC |
| Material | Copper |
| Finish | Electro -Tin Plated |
| Color | Yellow |
| Wire Range | 12-10 |

Dimension Information

| | |
|---------------------|------|
| Length (inches) | 1.06 |
| Diameter D (inches) | 0.11 |
| Stock Thickness | .04 |

Specifications

| | |
|---------------------|-----------|
| Temperature Rating | 105°C |
| Voltage Rating | 300V |
| Flammability Rating | UL 94 V-0 |

Tooling

| | |
|-------------------|--------------------------|
| Tool Charts | Available on Website |
| Application Tools | WT1455, ERG4001, ERG4003 |
| Recommended Tool | ERG4001 |

Packaging

| | |
|-----------------------|--------------------|
| T&B Order Multiple | 50 |
| T&B Inner Pack | 50 |
| Package in Units | 250 |
| Package Type | Standard |
| T&B Sold in UOM | Each |
| T&B Weight Per UOM | 4.38 lbs. per 1000 |
| Alternate Package Qty | RC55PT |

Application Support

| | |
|-------------------|----------------------|
| Overview | Available on Website |
| Wire Guide Tables | Available on Website |

Certifications

| | |
|-----------------|-----|
| RoHS Compliance | Yes |
|-----------------|-----|

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com