

Metal Clad Cable Termination Fittings & Accessories

T&B Catalog Number:

STE400

UPC Number:


78621099692

Status:

Active

Description:

Star Teck Extreme aluminum jacketed cable fittings, hub size-4 in.

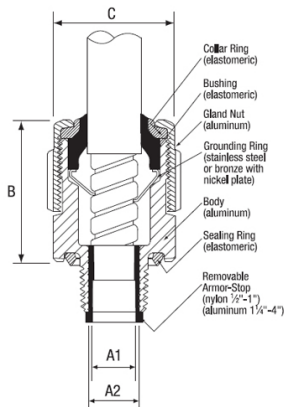

Features

Powergrip grounding ring.

Removable armor-stop for greater cable ranges.

Elastomeric collar ring/bushing for greater cable ranges.

Built-in jacket stripping gauge on gland nut.

Gland nut can be tightened with hammer and screwdriver.

Application

Provides means for passing armored, metal clad, jacketed cable through a bulkhead or enclosure in hazardous areas. (these fittings are suitable for hazardous areas when used with T&B sealing compound).

Form a mechanical grip and water and/or oil-resistant termination.

Provide grounding continuity of cable armor.

General

Material Aluminum

Strip Length (inches) 2 1/2

Dimension Information

Hub Size (inches) 4

Dimension B (inches) 5.415

Dimension C (inches) 6.400

A1:Throat Diameter Minimum (w/Armor Stop) 3.525

A2:Throat Diameter Minimum (wo/Armor Stop) 3.941

Range Over Jacket -Minimum (inches) 3.665

Range Over Jacket -Maximum (inches) 4.340

Range Over Armor -Minimum (inches) 3.550

Range Over Armor -Maximum (inches) 4.225

Strip Length (inches) 2 1/2

Packaging

Package in Units 2

T&B Sold in UOM Each

T&B Weight Per UOM 5.88 lbs. Each

Application Support

T&B Instruction Sheets ta01766-tb2

Product Specifications & Overview Available on Website

Product Brochure-Star Teck Extreme Available on Website

Director™ Cable Fittings

Notes

*Note

Fittings are suitable for hazardous areas when used with T&B sealing compound.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E 38947

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com