

Standard Barrel Copper Lug

T&B Catalog Number:

256-30695-237

UPC Number:


78621089663

Status:

Active

Description:

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, 750 kcmil Wire, 3/8" Bolt Size, 1" Hole Spacing, Tin Plated with Inspection Hole, Black 106

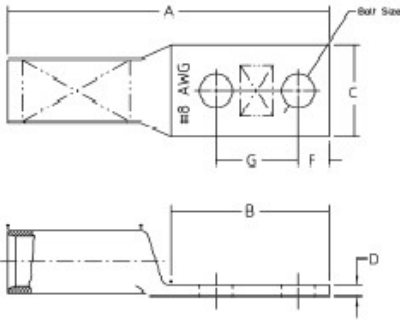

General

Material	Copper
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	106

Dimension Information

A (inches)	5.031
B (inches)	2.797
C (inches)	1.938
D (inches)	.281
E (inches)	1.328
F (inches)	.375
G (inches)	1

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	96 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com