

Long Barrel Copper Lug T&B Catalog Number:

54821BE

UPC Number:


78621019474

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 400 kcmil Wire, 3/8" Bolt Size, 1" Hole Spacing, Tin Plated Blind End, Blue 76

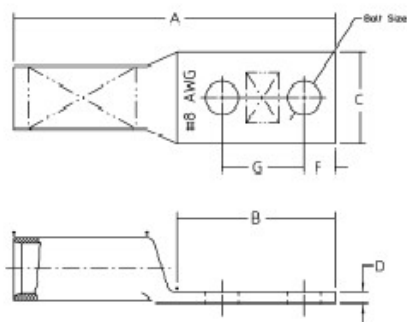

General

| | |
|-------------------|------------|
| Material | Copper |
| Finish | Tin Plated |
| Wire Size | 400 kcmil |
| Number of Studs | 2 |
| Stud Size | 3/8 |
| Bolt Hole Spacing | 1 |
| Tongue Angle | Straight |
| Barrel Length | Long |
| Barrel Shape | Standard |
| Tongue Width | Standard |
| Peep Hole | N |
| Marking | Standard |
| Hole Shape | Round |
| Die Color | Blue |
| Die Code | 76 |

Dimension Information

| | |
|------------|-------|
| A (inches) | 5.25 |
| B (inches) | 2.781 |
| C (inches) | 1.406 |
| D (inches) | .172 |
| E (inches) | .953 |
| F (inches) | .375 |
| G (inches) | 1 |

Tooling

| | |
|---------------------------|----------------------|
| Connector & Tooling Chart | Available on Website |
|---------------------------|----------------------|

Packaging

| | |
|--------------------|-----------------|
| T&B Order Multiple | 2 |
| T&B Inner Pack | 2 |
| Package in Units | 10 |
| T&B Sold in UOM | Each |
| T&B Weight Per UOM | 35 lbs. per 100 |

Application Support

| | |
|------------------------|----------------------|
| T&B Instruction Sheets | ta01025-tb2 |
| Product Overview | Available on Website |

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

| | |
|-----------------|-----|
| RoHS Compliance | Yes |
|-----------------|-----|

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com