


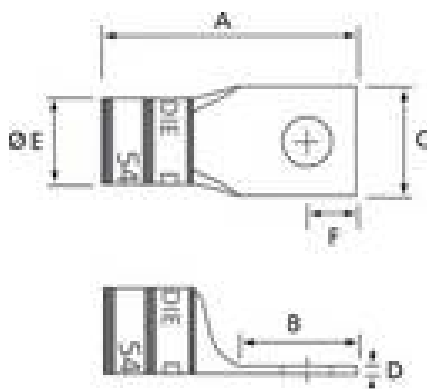

Standard Barrel Copper Lug

T&B Catalog Number:

54150

UPC Number:

78621054150

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, #1 AWG Wire, 1/2" Bolt Size, Tin Plated with Inspection Hole, Green 37

General

Material	Copper
Finish	Tin Plated
Wire Size	#1 AWG
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Green
Die Code	37

Dimension Information

A (inches)	2.10
B (inches)	1.25
C (inches)	0.76
D (inches)	0.11
E (inches)	0.47
F (inches)	1/2

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	20
Package in Units	200
T&B Sold in UOM	Each
T&B Weight Per UOM	4.5 lbs. per 100

Application Support

T&B Instruction Sheets	ta00675-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125

T&B Technical Support
MS 3B-50
8155 T&B Blvd.

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289

