

## Standard Barrel Copper Lug T&B Catalog Number:

54139BS

**UPC Number:**


78621095456

**Status:**

Active

**Description:**

Copper One-Hole Lug - Straight Standard Belled End Barrel - max 35KV, #4 AWG Wire, 5/16" Bolt Size, Tin Plated with Inspection Hole, Grey 29

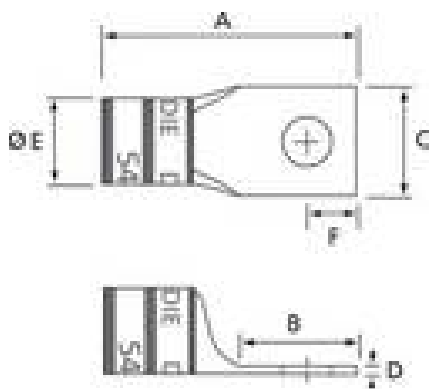

### General

Material	Copper
Finish	Tin Plated
Wire Size	#4 AWG
Number of Studs	1
Stud Size	5/16
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Grey
Die Code	29

### Specifications

Voltage Rating	600V to 35KV
----------------	--------------

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	2.9 lbs. per 100

### Application Support

Overview	Available on Website
----------	----------------------

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:

E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289

