

## Long Barrel Copper Lug T&B Catalog Number:

58826BEBS

**UPC Number:**


78621095544

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Belled End Barrel - max 35KV, 900 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Yellow 115

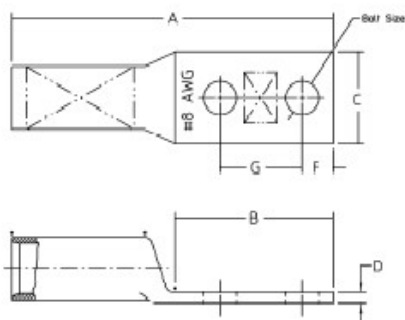

### General

Material	Copper
Finish	Tin Plated
Wire Size	900 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	115

### Dimension Information

A (inches)	6.49
B (inches)	2.8
C (inches)	2.27
D (inches)	0.3
E (inches)	1.5
F (inches)	0.63
G (inches)	1.75

### Specifications

Voltage Rating	600V to 35KV
----------------	--------------

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	3
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	1.52 lbs. Each

### Application Support

Overview	Available on Website
----------	----------------------

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)