

Standard Barrel Copper Lug

T&B Catalog Number:

256-30695-422

UPC Number:


78621064288

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, #6 AWG Wire, 1/2" Bolt Size, Tin Plated with Inspection Hole, Blue 24

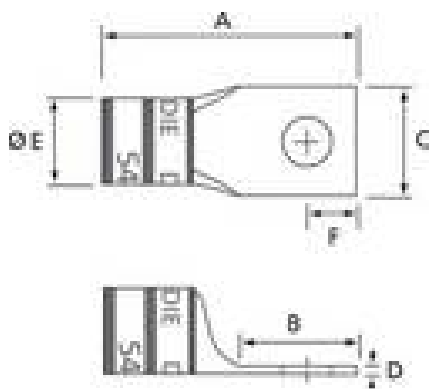

General

Material	Copper
Finish	Tin Plated
Wire Size	#6 AWG
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Blue
Die Code	24

Dimension Information

A (inches)	1.75
B (inches)	1.31
C (inches)	1.00
D (inches)	0.13
E (inches)	0.31
F (inches)	1/2

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	1
Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	9.38 lbs. per 100

Application Support

Product Overview	Available on Website
------------------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com