

Splice Connector

T&B Catalog Number:

2RBS14X

UPC Number:

78621070327

Status:

Active

Description:

Heat-Shrinkable Polyolefin Butt Splice Connector For Wire Range 16-14
Length 1.5 Diameter .26, Blue

WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Self-insulated with heat-shrinkable polyolefin and internally coated sealant. Upon completed installation, a fully sealed connection is achieved to protect the joint against the degrading effects of galvanic action, corrosion, and environmental exposure.

General

Insulation Type	Heat-Shrinkable Polyolefin
Terminal Series	RBS
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	16-14

Dimension Information

Maximum Insulation (inches)	.200
A (inches)	1.50
B (inches)	.26

Specifications

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	WT1255
Recommended Tool	ERG4255

Packaging


T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.44 lbs. per 100
Alternate Package Qty	RBBS22X

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

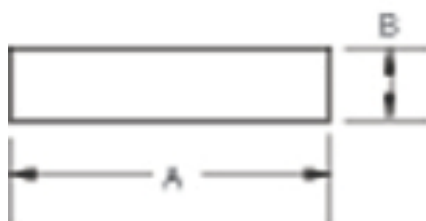

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com