

Long Barrel Copper Lug T&B Catalog Number:

54858BE

UPC Number:


78621089800

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, #1 AWG Wire, 5/16" Bolt Size, 7/8" Hole Spacing, Tin Plated Blind End, Green 37

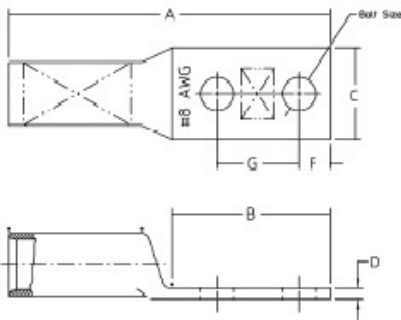

General

Material	Copper
Finish	Tin Plated
Wire Size	#1 AWG
Number of Studs	2
Stud Size	5/16
Bolt Hole Spacing	7/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Green
Die Code	37

Dimension Information

A (inches)	2.969
B (inches)	1.625
C (inches)	.672
D (inches)	.109
E (inches)	.469
F (inches)	.375
G (inches)	0.875

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	20
Package in Units	200
T&B Sold in UOM	Each
T&B Weight Per UOM	6.38 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com