



**Ring Terminal**  
**T&B Catalog Number:**

RBC14-38  
 78621089909  
 Active

**UPC Number:**  
**Status:**  
**Description:**

Insulated Nylon Ring Terminal For Wire Range 16-14 heavy duty Stud Size 3/8, Green

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Funneled Barrel Entry, Deep Internal Serrations, Brazed or overlapping seams.

**General**

Insulation Type	Insulated Nylon
Terminal Series	RBC
Material	Copper
Finish	Electro -Tin Plated
Color	Green
Wire Range	16-14 heavy duty
Stud Size	3/8

**Dimension Information**

Maximum Insulation (inches)	.210
Stock Thickness	.03
A (inches)	1.26
B (inches)	.63
C (inches)	.38
M (inches)	.94

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

**Tooling**

Tool Charts	Available on Website
Application Tools	WT2000, ERG4001
Recommended Tool	WT2130A


**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	250
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	1.38 lbs. per 100
Alternate Package Qty	RBC793

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

**Certifications**

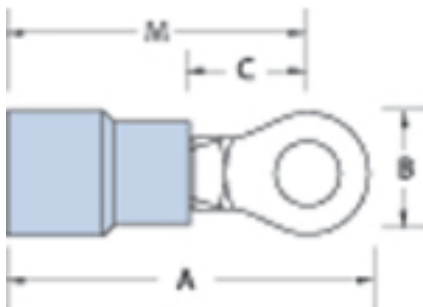

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)