

## Long Barrel Copper Lug T&B Catalog Number:

54880BE

**UPC Number:**


78621089811

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 750 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Black 106

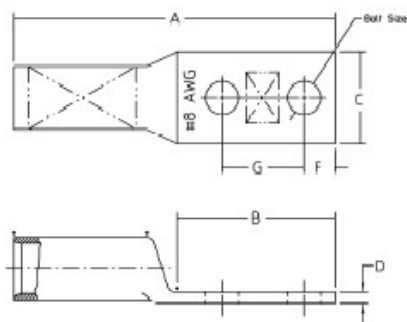

### General

Material	Copper
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	106

### Dimension Information

A (inches)	6.094
B (inches)	2.984
C (inches)	1.938
D (inches)	.25
E (inches)	1.333
F (inches)	.5
G (inches)	1.75

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	6
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	94.81 lbs. per 100

### Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)