



Long Barrel Copper Lug T&B Catalog Number:

54856BE

UPC Number:

78621089799

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, #2 AWG Wire, 5/16" Bolt Size, 3/4" Hole Spacing, Tin Plated Blind End, Brown 33

General

Material	Copper
Finish	Tin Plated
Wire Size	#2 AWG
Number of Studs	2
Stud Size	5/16
Bolt Hole Spacing	3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Brown
Die Code	33

Dimension Information

A (inches)	2.781
B (inches)	1.625
C (inches)	.578
D (inches)	.109
E (inches)	.406
F (inches)	.375
G (inches)	0.75

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	25
Package in Units	250
T&B Sold in UOM	Each
T&B Weight Per UOM	5.25 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website


Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

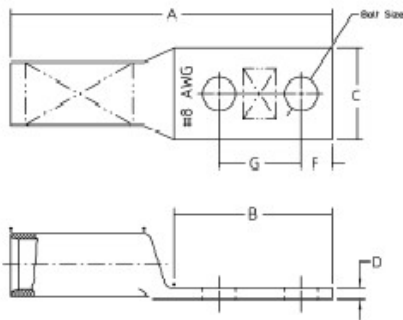

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com