

Metal Clad Cable Termination Fittings & Accessories

T&B Catalog Number:

STEX350

UPC Number:


78621099679

Status:

Active

Description:

Star Teck Extreme hazardous location aluminum jacketed cable fitting, hub size-3-1/2 in.

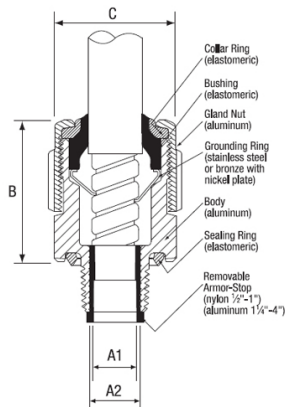

Features

Patented powergrip grounding ring.

Removable armor-stop for greater cable ranges.

Patented elastomeric collar ring/busing for greater cable ranges.

Built-in jacket stripping gauge on gland nut.

Gland nut can be tightened with hammer and screwdriver.

Application

Provides means for passing armored, metal clad, jacketed cable through a bulkhead or enclosure in hazardous areas. (these fittings are suitable for hazardous areas when used with T&B sealing compound).

Form a mechanical grip and water and/or oil-resistant termination.

Provide grounding continuity of cable armor.

General

Material	Aluminum
Strip Length (inches)	2 1/2
Sealing Compound Required-Putty (grams)	965
Sealing Compound Required-Liquid (cc)	464

Dimension Information

Hub Size (inches)	3 1/2
Dimension B (inches)	7.380
Dimension C (inches)	5.790
A1: Throat Diameter Minimum (w/Armor Stop)	2.531
A2: Throat Diameter Minimum (wo/Armor Stop)	2.864
Range Over Jacket -Minimum (inches)	2.670
Range Over Jacket -Maximum (inches)	3.270
Range Over Armor -Minimum (inches)	2.545
Range Over Armor -Maximum (inches)	3.145
Strip Length (inches)	2 1/2

Packaging

Package in Units	1
T&B Sold in UOM	Each
T&B Weight Per UOM	8.33 lbs. Each

Application Support

Product Specifications & Overview	Available on Website
-----------------------------------	----------------------

Notes

*Note

Fittings are suitable for hazardous areas when used with T&B sealing compound.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E 82038

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com