


90° Non-Metallic Connectors

For use with non-metallic liquid-tight conduit, type B only. 90° connector provides a smooth, gradual radius bend. Wiring is easily pulled or pushed through fitting and there are no sharp edges to strip wire. Produced from UV rated plastic for long outdoor life.



| CATALOG NUMBER | UPC/DCI/NAED MFG #018997 | TRADE SIZE | KO SIZE | UNIT PKG | STD PKG | DIM A | DIM B | DIM C |
|----------------|--------------------------|------------|---------|----------|---------|-------|-------|-------|
| NMLT9038 | 54903 | 3/8 | 1/2 | 10 | 50 | 2.325 | .562 | 2.440 |
| NMLT9050 | 54905 | 1/2 | 1/2 | 10 | 50 | 2.325 | .562 | 2.440 |
| NMLT9075 | 54907 | 3/4 | 3/4 | 10 | 50 | 2.550 | .545 | 2.840 |
| NMLT90100 | 54901 | 1 | 1 | 5 | 25 | 3.150 | .630 | 3.922 |
| NMLT90125 | 54912 | 1-1/4 | 1-1/4 | 5 | 25 | 4.440 | .645 | 4.650 |
| NMLT90150 | 54915 | 1-1/2 | 1-1/2 | 2 | 10 | 4.510 | .660 | 4.810 |
| NMLT90200 | 54920 | 2 | 2 | 2 | 10 | 5.062 | .670 | 5.320 |

Add suffix "BL" to Catalog # when ordering in black, for example NMLT9050BL.

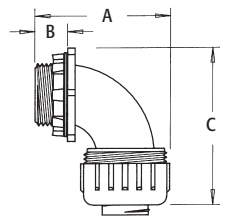

Liquid Tight