


SNAP²IT[®] Zero to 90[™] Non-Metallic Connectors

For use with non-metallic liquid-tight conduit, type B only. Push on installation. Produced from UV rated plastic for long outdoor life.

Liquid Tight

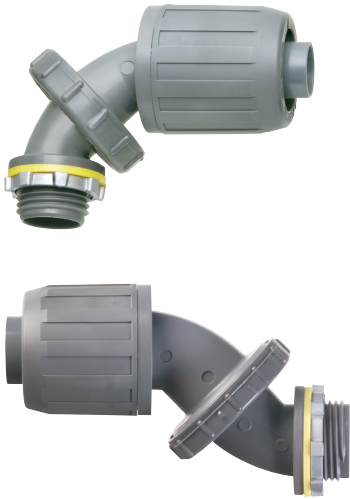



zero to 90[™]

| CATALOG NUMBER | UPC/DCI/NAED MFG #018997 | TRADE SIZE | KO SIZE | UNIT PKG | STD PKG | DIM A | DIM B | DIM C | DIM D |
|----------------|--------------------------|------------|---------|----------|---------|-------|-------|-------|-------|
| NMLT590 | 03900 | 1/2 | 1/2 | 10 | 50 | 3.165 | 2.435 | 3.594 | 2.007 |
| NMLT790 | 03902 | 3/4 | 3/4 | 10 | 50 | 3.875 | 2.900 | 4.200 | 2.623 |

Add suffix "BL" to Catalog # when ordering in black, for example NMLT590BL.

Factory order only. Minimum quantities required.

PATENTED.

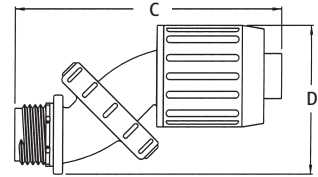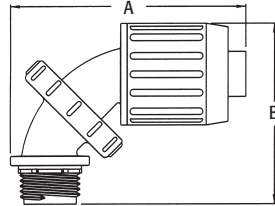

PUSHES
onto conduit...
NO TOOLS!



Adjusts for
ALL ANGLES...
from 0° to 90°!

To adjust the angle simply loosen the center nut, twist to the correct angle, and retighten.