


Item no.: 773-164
 Product description: PUSH-WIRE CONNECTOR FOR JUNCTION BOXES 4-CONDUCTOR TERMINAL BLOCK

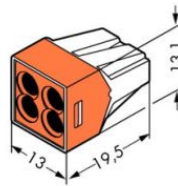

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Product group	7 (Push Wire Conn.)
pole count	4
Cross section [mm ²]	1.5 - 2.5 mm ²
Cross section [AWG]	16 - 12 AWG
Connection method	PUSH WIRE®
Number of strands	4
Cross section [mm ²]	1 - 2.5 mm ²
Cross section [AWG]	18 - 12 AWG
Wiring method	e
Number of strands	4
Measured voltage EN	400 V
Measured shock voltage	4 kV
Pollution degree	2
Current intensity EN	24 A
Weight	2.677 g
Color	orange
No. of connection Points	4
No. of potentials	1
Height	13.1 mm
Height	0.516 in

Width
Width

13 mm
0.512 in



Depth	19.1 mm
Depth	0.752 in
Strip length from	10 mm
Strip length to	13 mm
Strip length	0.45 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
773-164	CSA	154112-1059435	600	20	12-18

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected