
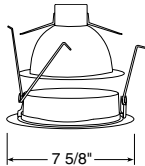


 


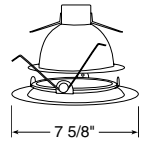


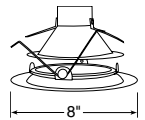


 









Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_


 


 


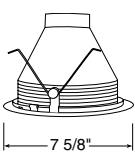


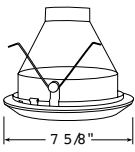


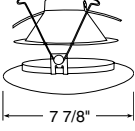


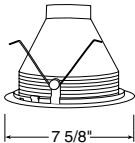

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p><b>Frosted Lens with Reflector</b></p>	 <p>7 5/8"</p>		<p><b>239 WH</b> 6" Lensed Frosted Lens Trim - White</p>	<p>IC2: 40W A19, 35W PAR30L TC2: 100W A19, TC2R: 75W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating)</p>
* Do not use reflector shipped with trim for LED Housing				
 <p><b>Albalite</b></p>	 <p>8"</p>		<p><b>20 PW</b> 6" Lensed Albalite Trim - Plastic White <b>20 WH</b> 6" Lensed Albalite Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 70W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p><b>Albalite Lends with Reflector</b></p>	 <p>7 5/8"</p>		<p><b>220 PW</b> 6" Albalite Lens With Reflector Trim - Plastic White <b>220 WH</b> 6" Albalite Lens With Reflector Trim - White</p>	<p>ICPL6: 26W, 32W (26W rating) PL6: 42W (26W rating)</p>
 <p><b>Albalite with Reflector</b></p>	 <p>8"</p>		<p><b>240 PW</b> 6" Lensed Albalite with Reflector Trim - Plastic White <b>240 WH</b> 6" Lensed Albalite with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 ICPL6: 18W PL6: 18W APT2: 75W A19</p>
 <p><b>Drop Oval</b></p>	 <p>8"</p>		<p><b>21 PW</b> 6" Lensed Drop Opal Trim - Plastic White <b>21 WH</b> 6" Lensed Drop Opal Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 75W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p><b>Drop Oval with Reflector</b></p>	 <p>8"</p>		<p><b>241 PW</b> 6" Lensed Drop Opal with Reflector Trim - Plastic White <b>241 WH</b> 6" Lensed Drop Opal with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 IC21/IC21R: 40W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W (26W rating) PL6: 18W, 42W (26W rating) APT2: 100W A19</p>
* Do not use reflector shipped with trim for LED Housing				
 <p><b>Drop Oval with Reflector</b></p>	 <p>8"</p>		<p><b>271 PW</b> 6" Lensed Drop Opal with Reflector Trim - Plastic White</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating)</p>

Housing and trim can be ordered together or separate, but will always ship separately.

# 6" TRIM SERIES LENSED

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p><b>Frosted Lens with Clear Center</b></p>	 <p>7 3/8"</p>		<p><b>242 ABZ</b> 6" Lensed Frosted Lens with Clear Center Trim - Classic Aged Bronze  <b>242 SC</b> 6" Lensed Frosted Lens with Clear Center Trim - Satin Chrome  <b>242 WH</b> 6" Lensed Frosted Lens with Clear Center Trim - White</p>	<p>IC2: 75W PAR38, TC2/ TC2R: 120W PAR38            IC22/ IC22 W/ IC22 S/ IC22R: 45W PAR38            IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM            TC22LED: G4 09LM/ G4 14LM/ G4 20LM            ICPL6: 26W, 32W            PL6: 42W (32W rating)            APT2: 120W PAR38</p>
 <p><b>Fresnel</b></p>	 <p>8"</p>		<p><b>22 WH</b> 6" Lensed Fresnel Trim - White</p>	<p>IC2: 40W A19, TC2/ TC2R: 75W A19            IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM            TC22LED: G4 09LM/ G4 14LM/ G4 20LM            ICPL6: 26W            PL6: 42W (32W rating)            APT2: 75W A19</p>
 <p><b>Baffle, Regressed Frosted Dome Lens</b></p>	 <p>7 5/8"</p>		<p><b>2330 BWB</b> 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - Black Baffle, White Trim Ring  <b>2330 WWB</b> 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - White Baffle, White Trim Ring</p>	<p>ICPL6: 18W, 26W, 32W            PL6: 18W, 42W (32W rating)            IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM            TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p><b>Beveled Frame Frosted Dome Lens</b></p>	 <p>7 5/8"</p>		<p><b>6101 ABZ</b> 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Classic Aged Bronze  <b>6101 SC</b> 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Satin Chrome  <b>6101 WH</b> 6" Lensed Beveled Frame with Frosted Dome Lens Trim - White</p>	<p>ICPL6: 18W, 26W, 32W            PL6: 18W, 42W            IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM            TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p><b>Decorative Swirled Etched Opal Glass Trim</b></p>	 <p>7 7/8"</p>		<p><b>243 WH</b> 6" Decorative Swirled Etched Opal Glass Trim - White</p>	<p>IC2: 60W A19            TC2/ TC2R: 100W A19            IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM            TC22LED*: G4 09LM/ G4 14LM/ G4 20LM            ICPL6: 26W            PL6: 42W (32W rating)</p>
* Do not use reflector shipped with trim for LED Housing				
 <p><b>Wall Wash Fluted Drop Opal Trim</b></p>	 <p>7 5/8"</p>		<p><b>9900 WH</b> 6" Wall Wash Fluted Drop Opal Trim - White</p>	<p>IC2: 60W A19, TC2/ TC2R: 75W A19            ICPL6: 13W, 18W, 26W, 32W            PL6: 13W, 18W, 26W            APT2: 75W A19</p>

Housing and trim can be ordered together or separate, but will always ship separately.