

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_


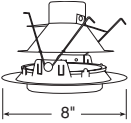


 


 


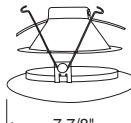


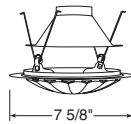


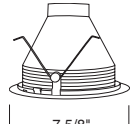


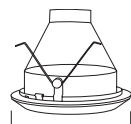

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

Trim Series	Dimensions	Aperture	Catalog No.	Housing/Lamp Compatibility
 <b>Frosted Lens with Reflector</b>	 7 5/8"		<b>239-WH</b> - Frosted Lens, White Trim	IC2: 40W A19, 35W PAR30L TC2: 100W A19, TC2R: 75W A19 IC22 Series and IC23 Series: 40W A19, 35W PAR30L IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series* ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W ICPL632 Series: 32W, PL642 Series: 32W IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series TC922LEDG3 Series*, TC1422LED3 Series*
 <b>Albalite</b>	 8"		<b>20-PW</b> - Shower/Closet Light, Plastic White <b>20-WH</b> - White Trim	IC2: 40W A19 TC2/TC2R: 75W A19 IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series APT2: 75W A19 TC922LEDG3 Series, TC1422LED3 Series
 <b>Albalite Lens with Reflector</b>	 7 5/8"		<b>220-PW</b> - Shower/Closet Light, Plastic White <b>220-WH</b> - White Trim	ICPL626 Series: 26W, ICPL632 Series: 26W PL642 Series: 26W
 <b>Albalite with Reflector</b>	 8"		<b>240-PW</b> - Shower/Closet Light, Plastic White <b>240-WH</b> - White Trim	IC2: 60W A19 TC2/TC2R: 100W A19 ICPL/PL613: 13W, ICPL/PL618: 18W APT2: 100W A19
 <b>Drop Opal</b>	 8"		<b>21-PW</b> - Shower/Closet Light, Plastic White <b>21-WH</b> - White Trim	IC2: 40W A19 TC2/TC2R: 75W A19 IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series APT2: 75W A19 TC922LEDG3 Series, TC1422LED3 Series
 <b>Drop Opal with Reflector</b>	 8"		<b>241-PW</b> - Shower/Closet Light, Plastic White <b>241-WH</b> - White Trim	IC2: 60W A19, TC2/TC2R: 100W A19 IC21 Series: 40W A19 IC22 Series and IC23 Series: 40W A19 ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W, ICPL632 Series: 26W PL642 Series: 26W APT2: 100W A19

\*Do not use reflector shipped with trim for LED housing.

# 6" TRIM SERIES LENSED

Trim Series	Dimensions	Aperture	Catalog No.	Housing/Lamp Compatibility
 <p><b>Drop Opal with Reflector</b></p>	 <p>8"</p>		<p><b>271-PW</b> - Plastic White</p>	<p>ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W, ICPL632 Series: 32W PL642 Series: 32W</p>
 <p><b>Frosted Lens with Clear Center</b></p>	 <p>7 3/8"</p>		<p><b>242-ABZ</b> - Classic Aged Bronze Trim <b>242-SC</b> - Satin Chrome Trim <b>242-WH</b> - White Trim</p>	<p>IC2: 75W PAR38 TC2/TC2R: 120W PAR38 IC22 Series: 45W PAR38 IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W, APT2: 120W PAR38 IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series TC922LEDG3 Series, TC1422LED3 Series</p>
 <p><b>Fresnel</b></p>	 <p>8"</p>		<p><b>22-WH</b> - White Trim</p>	<p>IC2: 40W A19 TC2/TC2R: 75W A19 IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series ICPL626 Series: 26W, PL642 Series: 32W APT2: 75W A19 TC922LEDG3 Series, TC1422LED3 Series</p>
 <p><b>Decorative Swirled Etched Opal Glass</b></p>	 <p>7 7/8"</p>		<p><b>243-WH</b> - Opal Glass</p>	<p>IC2: 60W A19 TC2/TC2R: 100W A19 IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series* ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W ICPL632 Series: 32W, PL642 Series: 32W IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series</p> <p>*Do not use reflector shipped with trim for LED housing. TC922LEDG3 Series*, TC1422LED3 Series*</p>
 <p><b>Fluted Drop Opal</b></p>	 <p>7 5/8"</p>		<p><b>9900-WH</b> - White Trim</p>	<p>IC2: 60W A19 TC2/TC2R: 75W A19 ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 26W, APT2: 75W A19</p>
 <p><b>Baffle, Regressed Frosted Dome Lens</b></p>	 <p>7 5/8"</p>		<p><b>2330W-WH</b> - White Baffle, White trim <b>2330B-WH</b> - Black Baffle, White Trim</p>	<p>IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series* ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series TC922LEDG3 Series*, TC1422LED3 Series*</p> <p>*Do not use reflector shipped with trim for LED housing.</p>
 <p><b>Beveled Frame, Frosted Dome Lens</b></p>	 <p>7 5/8"</p>		<p><b>6101-ABZ</b> - Classic Aged Bronze Trim <b>6101-SC</b> - Satin Chrome Trim <b>6101-WH</b> - White Trim</p>	<p>IC22LEDGEN2/IC22SLEDGEN2/IC22RLEDGEN2/TC922LED Series* ICPL/PL613: 13W, ICPL/PL618: 18W ICPL626 Series: 26W, ICPL632 Series: 32W IC22LEDG3/IC22RLEDG3/IC922LEDG3/IC922RLEDG3 Series TC922LEDG3 Series*, TC1422LED3 Series*</p> <p>*Do not use reflector shipped with trim for LED housing.</p>