

 
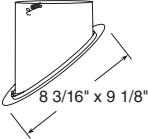

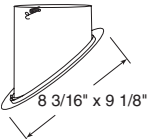

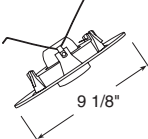

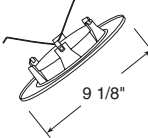


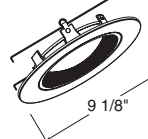

6" SLOPE TRIM SERIES SUPER SLOPE

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/Lamp Compatibility
 Baffle	 8 3/16" x 9 1/8"	5 1/2" x 6 7/8"	604W-WH - White Baffle, White Trim 604B-WH - Black Baffle, White Trim 604B-BL - Black Baffle, Black Trim 604B-ABZ - Black Baffle, Classic Aged Bronze Trim 604B-SC - Black Baffle, Satin Chrome Trim	IC928: 90W PAR38 TC928/TC928R: 150W PAR38 ICPL928-42: 42W Max ICPL928R-32: 32W Max IC928LED6/IC928LED9 Series
 Cone	 8 3/16" x 9 1/8"	5 3/4" x 7"	602W-WH - White, White Trim 602B-WH - Black Alzak®, White Trim 602C-WH - Clear Alzak®, White Trim 602G-WH - Gold Alzak®, White Trim 602HZ-SC - Haze, Satin Chrome Trim 602HZ-WH - Haze, White Trim 602WHZ-ABZ - Wheat Haze, Classic Aged Bronze Trim 602WHZ-WH - Wheat Haze, White Trim	IC928: 75W PAR30, 90W PAR38, 85W BR30 TC928/TC928R: 75W PAR30, 150W PAR38, 85W BR30 ICPL928-42: 42W Max ICPL928R-32: 32W Max IC928LED6/IC928LED9 Series
 Cylinder Spotlight in Baffle	 9 1/8"		606W-WH - White Cylinder with White Baffle, White Trim 606B-WH - Black Cylinder with White Baffle, White Trim	IC928/TC928/TC928R: 60W PAR16
 Lensed Flat Diffuser	 9 1/8"	 Wet Location	603W-WH - White Trim 603B-WH - White Trim	IC928: 50W PAR30 TC928/TC928R: 75W A19, 75W PAR30
 Baffle, Regressed Frosted Dome Lens	 9 1/8"	 Wet Location	6033W-WH - White Baffle, White Trim	ICPL928-42: 32W Max ICPL928R-32: 26W Max