



Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_


Contact/Phone: \_\_\_\_\_

# 6" ECONOMY UNIVERSAL IC REMODEL HOUSING

INCANDESCENT LAMPS

**IC22R**

## PRODUCT DESCRIPTION

IC Air-Loc® Remodel Housing • Energy efficient, sealed housing  
• IC Remodel Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in the ceiling from below • Secured in place by factory installed remodel springs • Can be completely covered with insulation  
• When used with Air-Loc Gasket (see accessories), stops infiltration and exfiltration of air, reducing heating and cooling costs • Trims shown with Air-Loc symbol  do not require gasket.

## PRODUCT SPECIFICATIONS

**Lamp** Lamp ratings based on trim selected—see reverse.

**Socket** Medium base porcelain with nickel-plated copper screw shell • Drop socket with spring to accommodate certain trim installation.



**Trims** Trim selection shown on reverse.

**Labels** U.L. listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps  
• Union made • UL Listed/CSA certified • Trims 239, 241 and 242 are wet location approved for covered ceiling applications  
• Trims 28, 29 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps**.

**Testing** All reports are based on published industry procedures; field performance may differ from laboratory performance.

Product specifications subject to change without notice.

## DIMENSIONS

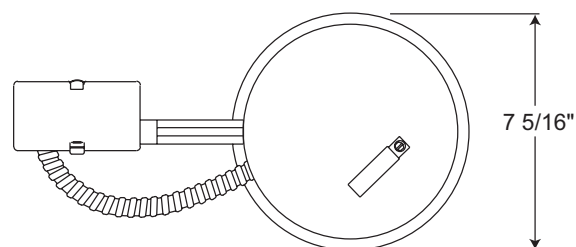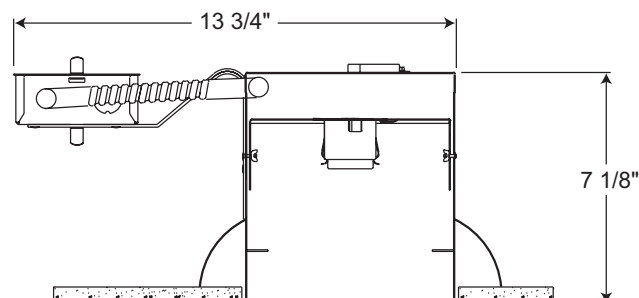

6 3/4" CEILING CUTOUT

## INSTALLATION

**Junction Box** Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (5) 1/2" knockouts, (4) Non-metallic sheathed cable connectors and ground wire • Knockouts equipped with pryout slots.

**Housing** IC housing, .032" aluminum sealed for Air-Loc Compliance • Double stack adjustable feature enables remodel spring to accommodate up to 1 3/4" ceiling thickness.

## PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating (max.)
IC22R	120V	A19/BR30/BR40/PAR16/PAR20/PAR30/PAR30L/PAR38/R20 (See reverse for max. trim rating)

## ACCESSORIES

Catalog No.	Description
ALG6R	Air-Loc Gasket














To order, specify catalog number.

# 6" ECONOMY UNIVERSAL IC REMODEL HOUSING

## INCANDESCENT LAMPS

### IC22R

#### TRIMS/LAMPS

Cat. No.	Description	Max. Lamp Rating		Cat. No.	Description	Max. Lamp Rating
<b>24B-WH</b> <b>24B-SC</b> <b>24B-ABZ</b> <b>24B-BL</b> <b>24W-WH</b>	Conical Black Baffle Conical Black Baffle Conical Black Baffle Conical Black Baffle Conical White Baffle	50W PAR30, 75W PAR30L, 65W BR30		<b>248W-WH</b>	R20 Eyeball in White Baffle	50W PAR20/R20
<b>25B-WH</b> <b>25B-SC</b> <b>25B-ABZ</b> <b>25B-BL</b> <b>25W-WH</b>	Straight Black Baffle Straight Black Baffle Straight Black Baffle Straight Black Baffle Straight White Baffle	50W PAR30, 65W BR30		<b>249B-WH</b> <b>249W-WH</b>	BR30 Eyeball in Black Baffle BR30 Eyeball in White Baffle	75W PAR30L, 65W BR30
<b>28B-WH ♦♦</b> <b>28W-WH ♦♦</b>	Conical Black Baffle Conical White Baffle	60W A19, 65W BR30, 75W PAR30/30L, 90W PAR38, 90W BR40		<b>264B-WH</b> <b>264W-WH</b>	PAR30 Adjustable - Black Baffle PAR30 Adjustable - White Baffle	50W PAR30
<b>29C-WH ♦♦</b> <b>29W-WH ♦♦</b>	Deep Cone Clear Cone Deep Cone White Cone	60W A19, 65W BR30, 75W PAR30/30L, 90W PAR38, 90W BR40		<b>267C-WH</b> <b>267G-WH</b> <b>267B-WH</b> <b>267HZ-WH</b> <b>267WHZ-WH</b>	PAR30 Adjustable - Clear Alzak® PAR30 Adjustable - Gold Alzak® PAR30 Adjustable - Black Alzak® PAR30 Adjustable - Haze PAR30 Adjustable - Wheat Haze	50W PAR30
<b>27C-WH</b> <b>27G-WH</b> <b>27B-WH</b> <b>27PT-SC</b> <b>27W-WH</b> <b>27HZ-WH</b> <b>27WHZ-WH</b> <b>27WHZ-ABZ</b>	Conical Cone in Clear Alzak® Conical Cone in Gold Alzak® Conical Cone in Black Alzak® Conical Cone in Pewter Alzak® Conical Cone in Gloss White Conical Cone in Haze Conical Cone in Wheat Haze Conical Cone in Wheat Haze	50W PAR30, 75W PAR30L, 65W BR30		<b>XR30101WH</b> <b>XR30101BL</b> <b>XR30101GP</b> <b>XR30101SL</b>	AVIO Square Gimbal Ring - White AVIO Square Gimbal Ring - Black AVIO Square Gimbal Ring - Graphite AVIO Square Gimbal Ring - Silver	75W PAR30
<b>244B-WH</b> <b>244W-WH</b>	Conical Black Baffle Conical White Baffle	75W PAR30L, 60W PAR30, 65W BR30		<b>239-WH ♦</b>	Frosted Lens	40W A19
<b>247C-WH</b> <b>247G-WH</b> <b>247B-WH</b> <b>247HZ-WH</b> <b>247WHZ-WH</b>	Cone - Clear Alzak® Cone - Gold Alzak® Cone - Black Alzak® Cone - Haze Cone - Wheat Haze	75W PAR30L, 65W BR30, 75W PAR30		<b>241-WH ♦</b> <b>241-PW ♦</b>	Drop Opal with Reflector Shower/Closet Light	40W A19
<b>250-WH</b> <b>250-SC</b> <b>250-ABZ</b>	Open Frame Open Frame Open Frame	65W BR30		<b>242-WH ♦</b> <b>242-SC ♦</b> <b>242-ABZ ♦</b>	Shower Trim, Frosted Lens with Clear Center	45W PAR38
<b>252-WH</b>	Regressed Open Frame	75W R/BR30		<b>9324-SC</b>	Luminous Disc	50W PAR30, 65W BR30, 75W PAR30
<b>231C-WH</b> <b>231G-WH</b> <b>231W-WH</b>	Multiplier - Clear Alzak® Multiplier - Gold Alzak® Multiplier - Gloss White	60W A19		<b>9702</b>	Luminous Collar	50W PAR30, 65W BR30, 75W PAR30L
<b>226B-WH</b> <b>226W-WH</b>	Black Cylinder w/Black Baffle White Cylinder w/White Baffle	60W PAR16		<b>9024W-WH</b>	White Octagonal w/White Baffle	50W PAR30, 65W BR30, 75W PAR30
<b>228-WH</b>	R20 Regressed Eyeball	50W PAR20/R20		<b>9524-SC</b>	Chrome Band	65W BR30, 50W PAR30, 75W PAR30L
<b>229-WH</b> <b>229-SC</b> <b>229-ABZ</b> <b>229-BL</b>	BR30 Regressed Eyeball BR30 Regressed Eyeball BR30 Regressed Eyeball BR30 Regressed Eyeball	75W PAR30L, 65W BR30		<p>Trim Size: 7<math>\frac{5}{8}</math>" O.D. (except Cat. Nos. 228, 229, 241, 9024, - 8" O.D., Cat. No. 9702 - 7<math>\frac{3}{4}</math>" O.D.).</p> <p>Trim Finish: ABZ - Classic Aged Bronze, BL - Black, GP - Graphite, PW - Plastic White (Polycarbonate material shower trim), SC - Satin Chrome, SL - Silver, WH - White.</p> <p>Alzak is a registered trademark of Alcoa Corp.</p> <p>Note: In Canada when insulation is present, Type IC fixtures must be used.</p>		

**Air-Loc** JUNO IC housings meet IECC Energy Code requirements per ASTM E283. Air-Loc® rated trims are pre-gasketed for minimum air leakage with IC housings.

♦ UL Listed for use in wet location.

♦♦ UL Listed for use in wet location with outdoor rated lamp.

\*\* NOTE: TR6 Trim Ring compatible with 24, 25, 27, 244, 247, 264, 267 trims.