

Overload Relays

Direct mount, manual/auto reset (stop/reset only). Requires contactor with sems clamp terminal (without quick connects) on load side. Select M for Digit 11 on p. 14.

Rated Current (Amps)		Max. Fuse Rating (Amps)	Max. Circuit Breaker Rating (Amps)	Catalog Number		List Price, GO-10C2
Min.	Max.			Class 10	Class 20	
0.16	0.26	1	15	RT1B	—	\$55.00
0.25	0.41	1	15	RT1C	—	55.00
0.4	0.65	3	15	RT1D	—	55.00
0.65	1.1	6	15	RT1F	—	55.00
1	1.5	6	15	RT1G	—	55.00
1.3	1.9	6	15	RT1H	—	55.00
1.8	2.7	10	15	RT1J	—	55.00
2.5	4.1	15	15	RT1K	RT12K	55.00
4	6.3	20	15	RT1L	RT12L	55.00
5.5	8.5	25	15	RT1M	RT12M	57.00
8	12	40	30	RT1N	RT12N	57.00
10	16	50	35	RT1P	RT12P	57.00
14.5	18	60	40	RT1S	RT12S	57.00
17.5	22	70	50	RT1T	RT12T	57.00
21	26	80	60	RT1U	RT12U	57.00
25	32	100	80	RT1V	RT12V	65.00
30	40	100	80	RT1W	RT12W	78.00



Remote Electrical Reset for RT1 Overload Relays

Voltage 50/60 Hz AC/DC	Catalog Number	List Price, GO-10C2
12	RTXRRB	\$55.00
24	RTXRRD	55.00
48	RTXRRG	55.00
110-120	RTXRRJ	55.00
220-240	RTXRRN	55.00
380-415	RTXRRU	55.00
440-480	RTXRRX	55.00

Panel Mount Overload Base Adapter

Catalog Number	List Price, GO-10C2
RTXP	\$12.00



NEMA Type 1 Enclosure Kits for Contactors & Starters

For 120A-150A contactor enclosures, contact your local GE Industrial Systems sales office.

Device	Rating	Catalog Number	List Price, GO-10DP
Contactors & Starters	25A-40A, 1-3 pole	CR453XE1A	\$42.00
Contactors	25A-40A, 4-pole and 50A-60A, 3-pole	CR353XE1BB	42.00
	75A-90A	CR353XE1BC	60.00
Starters	50A	CR353XE1AA	48.00



Enclosure with optional CLXR11 reset kit

Accessories for CR453XE1A Enclosure


Accessory	Catalog Number	List Price, GO-10C2	
Start/Stop Push Button without Light	CLXP1B	\$39.00	
Start/Stop Push Button with Light	115V	CLXP1C1	112.00
	230V	CLXP1C2	112.00
	460V	CLXP1C3	112.00
	575V	CLXP1C4	112.00
H-O-A Switch	CLXP1D	39.00	
On-Off Switch	CLXP1E	39.00	
Red Indicating Light (for use with H-O-A or On-Off selector switches) ^①	CLXP1F	67.00	
Reset Kit for Starter Enclosure	CLXR11	8.00	

^① Each kit has three resistors allowing light to be used with all voltages 110 through 600.


Outline Drawings

Dual Dimensions $\frac{\text{Inches}}{\text{mm}}$ for Estimating Only

Enclosure CR453XE1A, CR353XE1AA (without reset button), CR353XE1BB (with reset button)

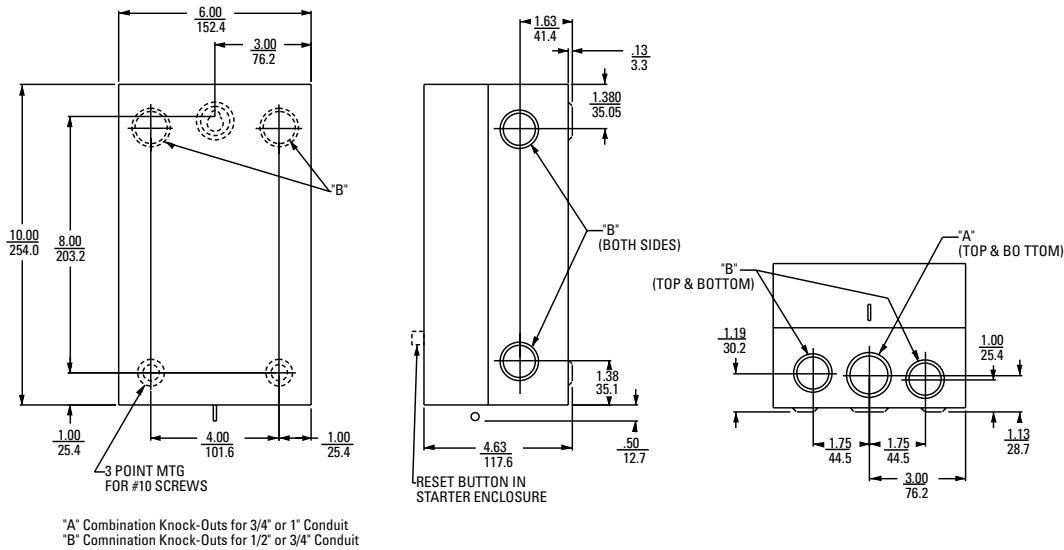

Enclosure CR353XE1BC

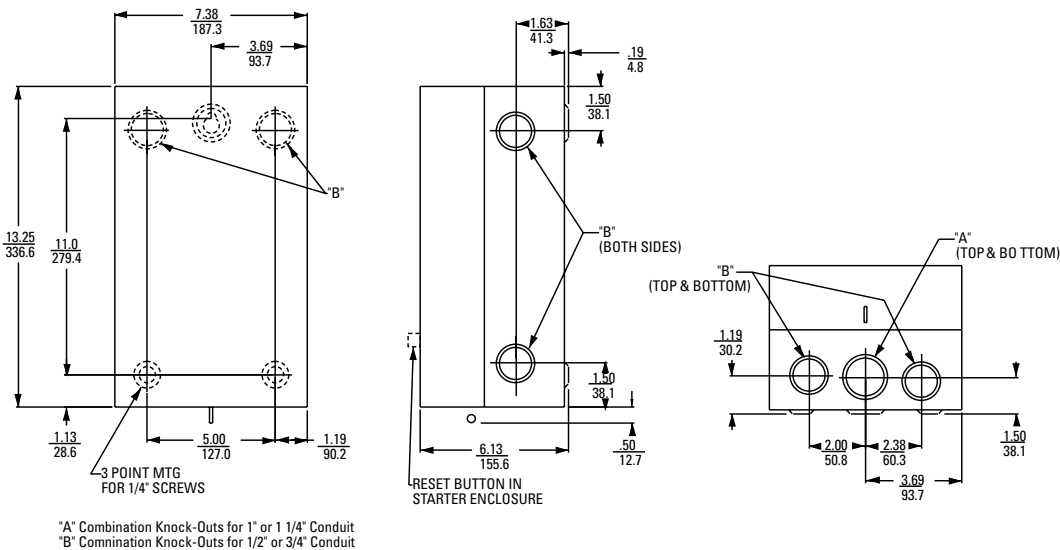

Definite Purpose Controls Full Voltage Contactors

CR453A, CR353

Standard
Accessories
25A-40A

Remote Electrical Reset for RT1 Overload Relays

Voltage 50/60 Hz AC/DC	Product Number	List Price GO-10C2
12	RTXRRB	\$55.00
24	RTXRRD	\$55.00
48	RTXRRG	\$55.00
110-120	RTXRRJ	\$55.00
220-240	RTXRRN	\$55.00
380-415	RTXRRU	\$55.00
440-480	RTXRRX	\$55.00



Remote Electrical Reset

Overload Base Adapter Panel Mount

Product Number	List Price GO-10C2
RTXP	\$12.00

Enclosure Kits NEMA Type 1

Contactor Prefix	Device	Rating	Product Number	List Price GO-10DP
CR453	Contactors/Starters	25A-40A, 1-3 pole	CR453XE1A	\$42.00
CR353	Contactors	25A-40A, 4-pole	CR353XE1BB	\$42.00
		50A-60A, 3-pole		
CR353	Contactors	75A-90A	CR353XE1BC	\$60.00
CR354	Starters	50A	CR353XE1AA	\$48.00



Start/Stop Push Button

Accessories for CR453XE1A Enclosure

Enclosure Accessory Type	Product Number	List Price GO-10C2
Start/Stop Push Button Without Light	CLXP1B	\$39.00
Start/Stop Push Button With Light—115 V	CLXP1C	\$112.00
Start/Stop Push Button With Light—230 V	CLXP2C	\$112.00
Start/Stop Push Button With Light—460 V	CLXP3C	\$112.00
Start/Stop Push Button With Light—575 V	CLXP1C4	\$112.00
H-O-A Switch	CLXP1D	\$39.00
On-off Switch	CLXP1E	\$39.00
Red Indicating Light (For use with H-O-A or ON/OFF selector switch)	CLXP1F ¹	\$67.00
Reset Kit (For starter enclosure)	CLXR11	\$8.00



H-O-A Switch

¹Each kit has three resistors allowing light to be used with all voltages 110 through 600.

Pneumatic Timers for CR453A Series

Type	Time Range	Contacts	Product Number	List Price GO-10C2
Time Delay On	0.1-30 seconds	1 NO-1 NC	BTLF30C	\$120.00
Time Delay On	1-60 seconds	1 NO-1 NC	BTLF60C	\$120.00
Time Delay Off	0.1-30 seconds	1 NO-1 NC	BTLF30D	\$120.00
Time Delay Off	1-60 seconds	1 NO-1 NC	BTLF60D	\$120.00

Surge Suppressors

Type	Voltage	Product Number	List Price GO-10C2
RC	24-48 VAC	BSLR2G	\$24.00
RC	50-127 VAC	BSLR2K	\$24.00
RC	130-240 VAC	BSLR2R	\$24.00
Diode	12-600 VAC	BSLDZ	\$24.00
Varistor	24-48 VAC/DC	BSLV3G	\$24.00
Varistor	50-127 VAC/DC	BSLV3K	\$24.00
Varistor	130-250 VAC/DC	BSLV3R	\$24.00
Varistor	380-500 VAC/DC	BSLV3U	\$24.00



On-Off Switch

Mechanical Latch Block for CR453A Series

Release Voltage	Product Number	List Price GO-10C2
24-32 VAC/DC	RMLFD	\$70.00
42-48 VAC/DC	RMLFG	\$70.00
110-125 VAC/DC	RMLFJ	\$70.00
208-277 VAC/DC	RMLFN	\$70.00
380-480 VAC/DC	RMLFU	\$70.00
500-600 VAC/DC	RMLFY	\$70.00



Reset Kit for Starter Enclosure



Publications and Reference: See Section 17 for a complete list of additional product-related publications