


## TracJack Stylistics Frame, four-port, Cloud White

OR-41900018-88

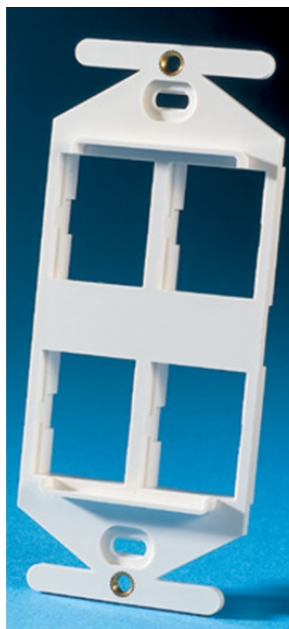

TracJack Stylistics Plastic Duplex Frame accepts four front-loading TracJack modules in the rectangular electrical mounting footprint of a GFCI outlet. It is compatible with many cable delivery systems that can house electrical duplex outlets

### features & benefits

- **Matches rectangular electrical outlet (GFI) footprint:** Supports use with electrical delivery system.
- **Field configurable with TracJacks:** Design or site flexibility for new or retrofit.
- **Supports TracJack footprint:** Broad offering of connector options.
- **Front load and access:** Connector access without removing plate.
- **Choice of colors:** Compatible with many environments.

### specifications

#### General Info

Color: Cloud White  
Footprint: TracJack  
Number Of Ports: 4  
Product Series: Clarity  
Type: Plates and Boxes

#### Assembly/Installation Information

Mounting Hardware Included: #6-32\*25 mm Screw, Binding Head (2 ea)

#### Listing Agencies/Third Party Information

CUL Listing No: E131600  
UL Listing No: E131600

UL Standard: Yes

### **Construction Information**

Component1: Plastic TracJack Mounting Frame

Material1: High Impact Thermoplastic ABS 94V-0

### **Dimensions**

Depth Metric: 11.43 mm

Height Metric: 103.88 mm

Height U S: 4.09"

Width Metric: 44.45 mm

### **Buy American Act Compliance**

Country of Origin: TAIWAN

Buy American Act Status: Trade Agreement Act Compliant