 

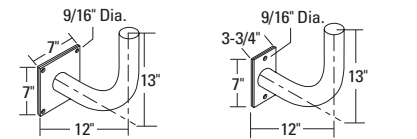
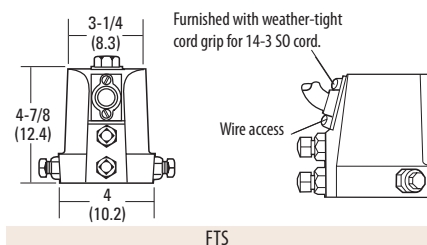
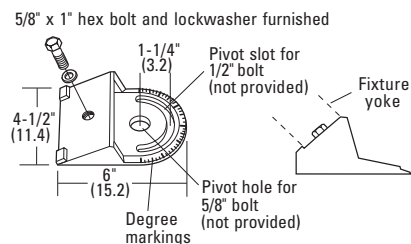


Catalog Number
Notes
Type


### FLOODLIGHTING, GARAGE & SPORTSLIGHTING

 NOM.	DESCRIPTION	GARAGE			SPORTS		FLOODLIGHTING										
		PGR	KPS	KACM	TSP	TV	ASF	DSXF	KFL	55	95	1705	TFA	TFR	TFL	TFM	
HS	House-side shield (glare shield).	■															
BDS	Bird-deterrent shroud.	□															
OJB	Offset junction box.	□															
RMG	Recessed mount in grid ceiling.		■														
SS	Stainless steel, ceiling-mount housing (alloy 304 stainless steel).		■														
AH	Above horizontal aiming.					■											
CF	Charcoal filter; must use with heavy-duty shroud.				■	■											
FCRA <sup>1</sup>	Crossarm adapter for horizontal mounting (use with yoke mount only).				□		□	□	□				□	□	□	□	
FCRA45 <sup>1</sup>	Crossarm adapter for horizontal mounting 45° (use with yoke mount only).				■		□	□	□				□	□	□	□	
SLR	Stainless steel lens rings.				■	■											
IBL	Internal bottom louver; cannot order IBL and TVUV together.					■											
FRWB <sup>1</sup>	Radius wall bracket; 2-3/8 diameter (use with slipfitter mount only).				□	□	□	□	□	□	□	□	□	□	□	□	□
FSAB <sup>1</sup>	Steel angle bracket (use with yoke mount only).				□	□	□	□	□	□	□	□	□	□	□	□	□
FSPB <sup>1</sup>	Steel square pole bracket (for use with existing poles). 2-3/8" diameter (use with slipfitter mount only).				□	□	□	□	□	□	□	□	□	□	□	□	□
FPMB <sup>1</sup>	Pipe/wood/pole/wall mounting bracket. Mounts to 2" schedule 40 pipe (use with yoke mount only).				□	□	□	□	□	□	□	□	□	□	□	□	□
FWPB <sup>1</sup>	Wall bracket (pipe) (use with yoke mount or standard TV mount).				□	□	□	□	□	□	□	□	□	□	□	□	□
FTS <sup>1</sup>	Tenon slipfitter (14g cord); fits 2-3/8" to 2-7/8" OD tenon (yoke mount only). For 12g cord, order as: FTS CG2. For DSXF2 or DSXF3 (16g cord), order as: FTS CG6				□	□	□	□	□	□	□	□	□	□	□	□	□
TVTS <sup>1</sup>	Tenon slipfitter for 14g cord; fits 2-3/8" to 2-7/8" OD tenon.				□	□											
TFMST <sup>1</sup>	Tenon slipfitter for 1/2" threaded knuckle; fits 1-1/4" to 2-3/8" OD tenon. For ground mount only.									□							□
DSXF1/2TS	Tenon slipfitter for 1/2" threaded knuckle; fits 1-1/4" to 2-3/8" OD tenon.									□							
TVUV	Upper visor; cannot be used with IBL.					□											
FCX2 <sup>1</sup>	2-light wood pole crossarm (use with yoke mount or standard TV mount).				□	□	□	□	□	□	□	□	□	□	□	□	□
FCX3 <sup>1</sup>	3-light wood pole crossarm (use with yoke mount or standard TV mount).				□	□	□	□	□	□	□	□	□	□	□	□	□
FCX4 <sup>1</sup>	4-light wood pole crossarm (use with yoke mount or standard TV mount).				□	□	□	□	□	□	□	□	□	□	□	□	□
YK	Yoke mount, painted.	□	■	■	■	■	■	■	■	■	■	■	■	■	■	■	■
YK62	Yoke mount with 3' 16-gauge cord (black)									■							
EY	Extended yoke.													■	■		
THK	Threaded knuckle mount. 3/4" for ASF1 (std) and DSXF3. 1/2" for TFM, KFL (std), DSXF1, DSXF2 (THK option).								■	■	■						
IS	Integral slipfitter; fits 2-7/8" max. OD with TFA, 2-3/8" with TFL and TFR.													■	■	■	


■ = Available as an option, shipped included  
 □ = Available as an accessory, shipped separately

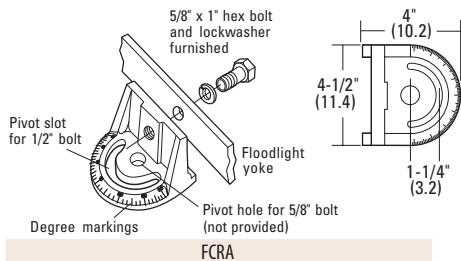

EPA: 1.4 sq. ft.  
Weight: 20 lbs.







EPA: 3.9 sq. ft.  
Weight: 56 lbs.

 

EPA: 4.8 sq. ft.  
Weight: 64 lbs.



EPA: 4.8 sq. ft.  
Weight: 64 lbs.

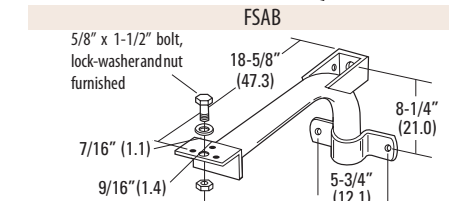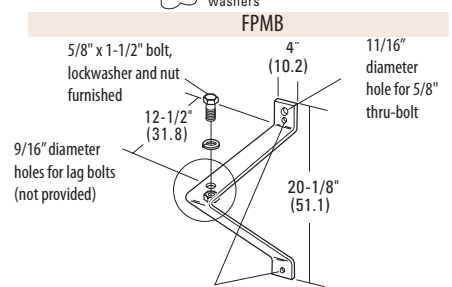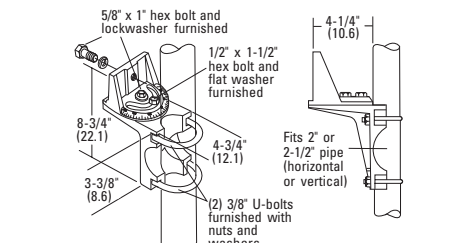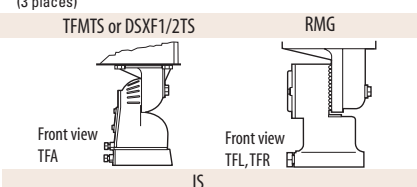


- Notes**
- For accessory, order as separate catalog number. Must specify finish.
  - Ships standard with TSP. Order as separate catalog number for other families.
  - N/A with DSXF1.
  - N/A with DSXF3.


# FLOODLIGHTING

NOMENCLATURE	DESCRIPTION	ASF	DSXF	KFL/WFL	55	95	170S	TFA	TFR	TFL	TFM
BD <sup>2</sup>	Barn doors	<input type="checkbox"/>		<input type="checkbox"/>							
BV <sup>2</sup>	Bottom visor			<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>		<input type="checkbox"/>			
BVG	Bubble vandal guard	<input type="checkbox"/>		<input type="checkbox"/>							
CV <sup>2</sup>	Concentric visor					<input type="checkbox"/>					
EV	Eggcrate visor (black finish)	<input type="checkbox"/>		<input type="checkbox"/>							
FV <sup>2</sup>	Full visor	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>		<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
FV/BVG <sup>2</sup>	Full visor and bubble vandal guard	<input type="checkbox"/>									
GS <sup>2</sup>	Glare shield (upper or bottom visor)	<input type="checkbox"/>									
GV <sup>2</sup>	Glare visor				<input type="checkbox"/>	<input type="checkbox"/>					
HLV	Horizontal louver (black finish)			<input type="checkbox"/>							
VG <sup>1</sup>	Vandal guard		<input type="checkbox"/>					<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
UV <sup>2</sup>	Upper visor			<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
UBV <sup>2</sup>	Upper visor and bottom visor		<input type="checkbox"/>								
UV/BVG <sup>2</sup>	Upper visor and bubble vandal guard			<input type="checkbox"/>							
VLV	Vertical louver (black finish)			<input type="checkbox"/>							
WG	Wire guard		<input type="checkbox"/>	<input type="checkbox"/>				<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>


= Available as an accessory, shipped separately. Specify family as prefix.

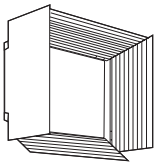


BD – Barn doors (KFL and ASF)

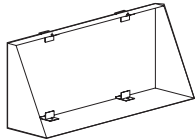


BV – Bottom visor (KFL)

 


BV – Bottom visor (55/95)

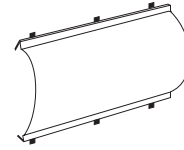


BVG – Vandal guard (KFL and ASF)

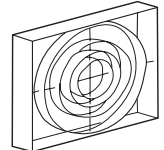


CV – Concentric visor (95)

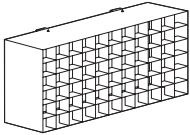


EV – Eggcrate visor (KFL and ASF)

 


FV – Full visor (KFL and ASF)

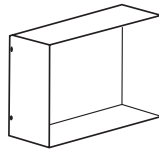


FV – Full visor (55/95)

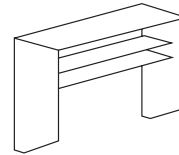


GV – Glare visor (55/95)

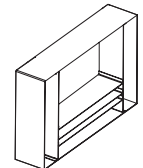


HLV – Horizontal louver (KFL)

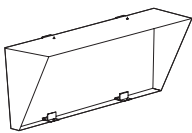


UV – Upper visor (KFL)

 


UV – Upper visor (55/95)

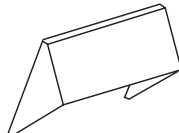


UV – Upper visor (170)

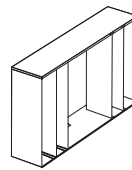


VLV – Vertical louver (KFL)

 


WG – Wire guard (KFL)

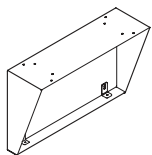


GS – Glare shield (ASF)

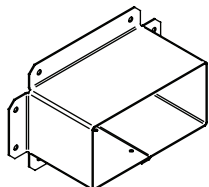


FV – Full visor (DSXF1)

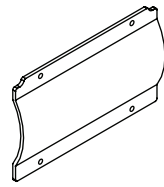

VG – Vandal guard (DSXF1)

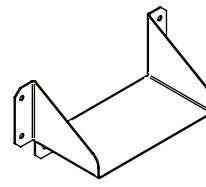

UBV – Upper or bottom visor (DSXF1)

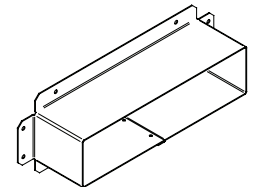


FV – Full visor (DSXF2)


### Notes

- 1 Vandal guards are compatible with all wattages.
- 2 For accessory, must specify finish.
- 3 DSXF3 only.


# FLOODLIGHTING

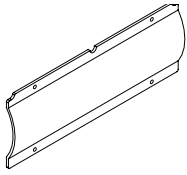


VG – Vandal guard (DSXF2)

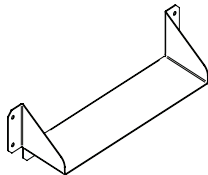


UBV – Upper or bottom visor (DSXF2)

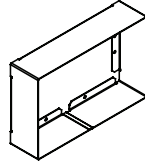


FV – Full visor (DSXF3)

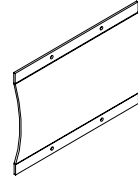


VG – Vandal guard (DSXF3)

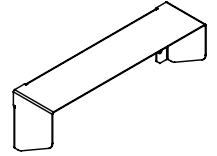


UBV – Upper or bottom visor (DSXF3)

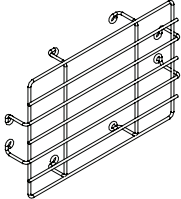


WG – Wire guard (DSXF3)

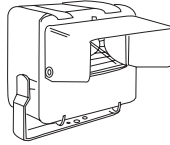


FV – Full visor (TFA)

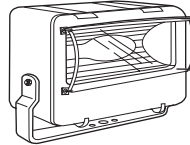


VG – Vandal guard (TFA)

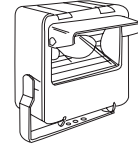


UV – Upper visor (TFA)

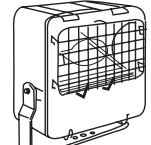


WG – Wire guard (TFA)

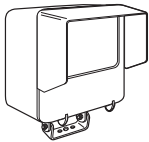


FV – Full visor (TFL)

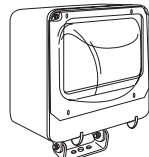


VG – Vandal guard (TFL)

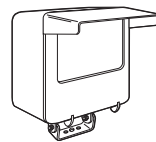


UV – Upper visor (TFL)

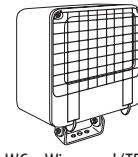


WG – Wire guard (TFL)

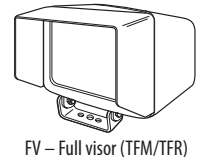


FV – Full visor (TFM/TFR)

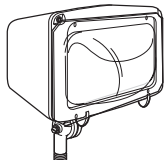

VG – Vandal guard (TFM/TFR)

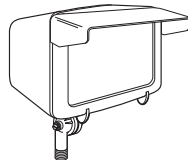

UV – Upper visor (TFM/TFR)

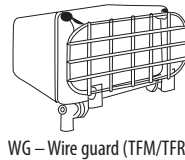

WG – Wire guard (TFM/TFR)