

# F13S-L

Project:

Contractor:

## LED COMPACT FLOOD LIGHT

10W to 48W (936 lumens to 4284 lumens)



Not all products are qualified on the DLC QPL. To view our DLC qualified products, please consult the DLC Qualified Products List at [www.designlights.org/search](http://www.designlights.org/search).

IP RATING  
**65**



Approvals:  
cULus  
Suitable for wet locations


### DESCRIPTION

The F13S-L series is a family of highly efficient and affordable compact LED flood lights in four different lumen packages ranging from 936 lumens to 4284 lumens. Each fixture has a modern thin design with an aluminum die-cast housing, standard with a black powder coat finish. The fixture comes with either a 1/2" NPT swivel mount or a trunnion mount.

### TECHNICAL SPECIFICATIONS

- Aluminum die-cast housing with powder coat finish (standard is black)
- White housing is optional
- Input voltage: 120-277V
- High quality, long life LEDs
- Estimated lifespan of 50,000 hours
- 4000K colour temperature
- Low starting temperature of -40°C

### DIMENSIONS

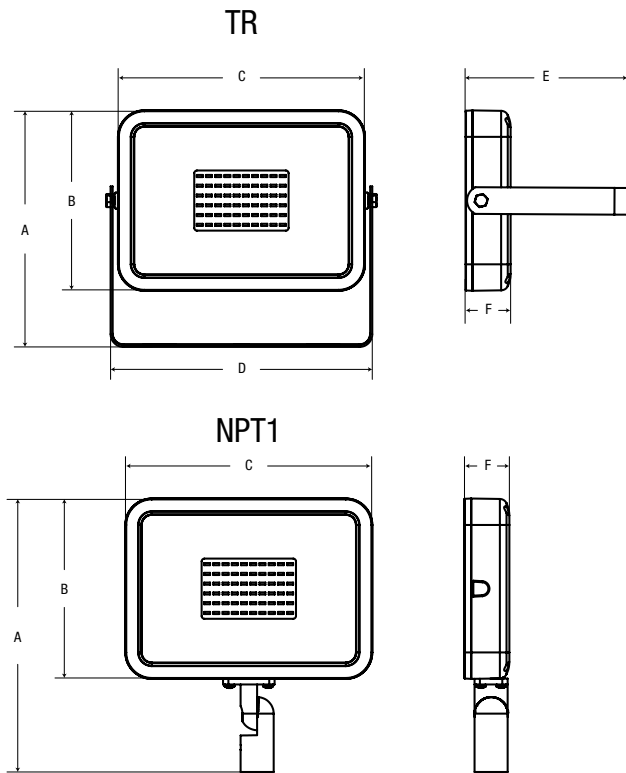

Mounting	Lumen package	A (in)	B (in)	C (in)	D (in)	E (in)	F (in)
TR	A1	5.354	3.740	5.118	5.512	3.504	1.102
	A2	7.402	5.315	7.283	7.677	4.646	1.378
	A3-A4	8.307	6.614	9.055	9.488	5.630	1.654
NPT1	A1	6.929	3.740	5.118	N/A	N/A	1.024
	A2	8.504	5.315	7.283	N/A	N/A	1.378
	A3-A4	10.079	6.614	9.055	N/A	N/A	1.654

### LUMEN AND SPECIFICATION CHART

General specifications			40K					Lumen maintenance		
Lumen package	Wattage (W)	Voltage (V)	Lumens	lm/W	PF	THD	BUG	Reported L70 40K	Calculated TM21 40K	LM80 @ (Hrs)
A1	10	120-277	936	90.2	0.9	13.30%	110	>36 000	203 000	6000
A2	19	120-277	1748	90.8	0.9	13.30%	110			
A3	30	120-277	2754	91.5	0.9	13.30%	110			
A4	48	120-277	4284	89.6	0.9	13.30%	210			

### ORDERING GUIDE

Series	Lamp type	Lumen package	Voltage	Color temperature	Casting colour	Options (mandatory selection)
F13S	L - LED	A1 A2 A3 A4	2 - 120-277V	40K - 4000K	Blank - Black (standard) WH - White	TR - trunnion mount NPT1 - 1/2" NPT swivel mount