




WHITE

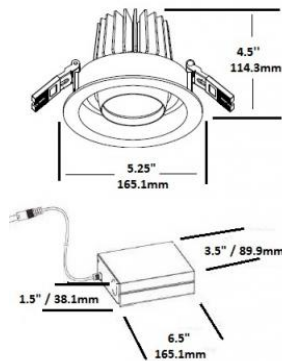

## EG-LED-500

### 5" HIGH PERFORMANCE EDGE SERIES - 20W

#### Product codes

- EG500-20W-3K-38WH : WHITE - 3K
- EG500-20W-3K-38BK : BLACK - 3K
- EG500-20W-3K-38SV : SILVER - 3K
- EG500-20W-4K-38WH : WHITE - 4K
- EG500-20W-4K-38BK : BLACK - 4K
- EG500-20W-4K-38SV : SILVER - 4K

Integrated COB (chip on board) technology offers low-energy, long lasting performance with outstanding light outputs of 1800 LUMENS.

Includes a standard 38 degree reflector and optic lens set in a convenient pivoting gimbal for optimal light adjustment. A custom 24 degree reflector and solite lens are optionally available.

The body is constructed of die cast aluminum, with junction box manufactured in aluminum extrusion. For easy and quick installation the unit comes with pressure-fit spring clips, thermal protection and quick connect wire connectors. Dimmable driver included.

Well suited for commercial and residential applications, as well rated for damp locations. For an IC application, the use of an isolated box is recommended ( NDR #IB400-EG)

#### Données techniques

Cutting hole	4.75" (120.7 mm)
Beam Angle	38° ± 1/2
Adjustment angle	35° ± 1/2
Head Rotation	360° ± 1/2
Color Temperature	3000K / 4000K
Mounting Plate	MP/AMP/MPHB 450
CRI	>80
Dimmable	Y
Bulb Life	50000 hrs
Light Output - Lumen	1800
Operating Temperature	-40c + 40c
Voltage	120V

VOLTAGE - Special Order 277V

VOLTAGE - Special Order 247V