

EM150S24DC DIFFUSION LED MAGNETIC DRIVER

DESCRIPTION


Diffusion EM150S24DC is a Magnetic Low Voltage, 24VDC Dimmable LED Driver

FEATURES

- * Nema 3R for Indoor/Outdoor use
- * Uses an assortment of dimmers including CFL/LED style
see dimmer compatibility list
- * Divider built into the enclosure so no need for a box
- * Standard 3/8" KO
- * Max load rated

SPECIFICATIONS

Input Voltage: 120V 60Hz
 Max Input Current at full load: 1.5A
 Output Voltage without load: 25.3VDC
 Output Voltage: 23.5V DC
 Max Wattage: 150W
 Max Output Current: 6.2A
 Efficiency: 88%
 Load regulation: 0%
 Ripple: 0%

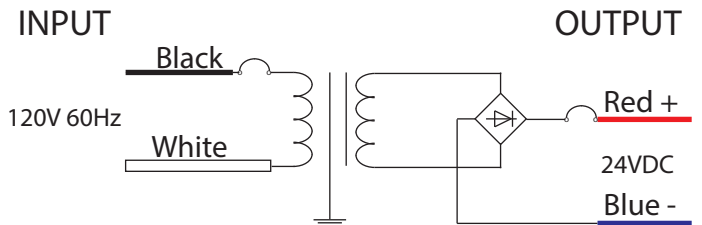

Project: _____
 Type: _____
 Date: _____
 Part #: _____