

SLEXW

RAINSTORM NEMA4X/EEMAC4X



Approvals:
CSA Certified to C22.2 #141.15 and C860



DESCRIPTION

The SLEXW series of NEMA4X and EEMAC4X rated weatherproof signs is designed to operate in extreme environments. The fully gasketed housing is suitable for outdoor and wash-down locations. Available in AC only, AC/DC and internally self-powered versions.

CIRCUITRY - AC & AC/DC

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 1.9W power consumption single or double face
- Emergency DC wattages as follows:

UDC					IB	
6V	12V	24V	120V	347V	120V	347V
1.0W	1.4W	3.5W	1.9W	1.8W	3.1W	2.9W


CIRCUITRY - SELF-POWERED

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2W power consumption single or double face
- High-performance, sealed Ni-Cad battery
- 90 minutes emergency duration (standard)
120 minutes emergency duration is optional
- Solid state transfer and battery charger

MECHANICAL

- Heavy-duty glass fibre reinforced polyester construction
- Lens with one piece, molded gasket
- Four integral mounting holes (one per corner) protected behind polycarbonate cover
- Lens secured to housing with four oversized captive screws
- The housing is supplied standard in a grey industrial finish. Face plate standard grey. Black is an option for indoor use only

DIMENSIONS

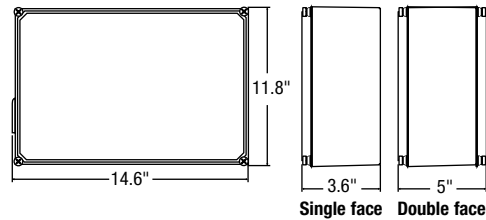

ORDERING GUIDE

Series	Nbr of faces	Mounting	Frame color	Mask color	DC Voltage	Options†
SLEXW	1 - Single face 2 - Double face	CM - Ceiling mount WM - Wall mount EM - End mount PM - Pendant mount	GY - Grey	GY - Grey (standard)	NDC - AC only UDC - Universal DC backup voltage 6, 12 or 24VDC IB - Self-powered for 90 minutes	WG* , BO , WO , OP , TP

† For detailed options descriptions, please consult the options page.

* Specify mounting.