




WHITE &
CHROME

WHITE

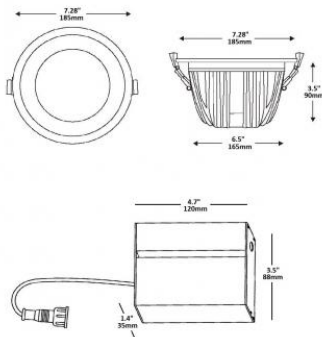

APX-LED-610

6" HIGH PERFORMANCE APEX SERIES - 20W

Product codes

APX610-1520-3K-WH : WHITE-WHITE 3K

APX610-1520-3K-WCH : WHITE-WHITE 3K

APX610-1520-4K-WH : WHITE-WHITE 4K

APX610-1520-4K-WCH : WHITE-CHROME 4K

This high performance LED recessed downlight comes with a pressure-fit spring clips for an easy installation. Integrated LED technology offers low-energy, long lasting performance with outstanding light outputs up to 2500 lumens.

The polycarbonate 60 degree reflector is designed for maximum reflection efficiency. The deep regressed diffuser is designed to eliminate the glare from the high powered LED. It is available with a White or Chrome reflector.

The body is constructed of die cast aluminum in 3", 4", 6" & 8" trim sizes with a junction box manufactured in aluminum extrusion. Designed to replace existing CFL/PL, fluorescent or incandescent fixtures. Well adapted for any new, remodel or old commercial applications. For easy and quick installation, the unit comes with pressure-fit spring clips, quick connect wire connectors and IC rated.

It features a 0-10V dimmable driver (120-277V). An optional 120V dimmable driver is available.

Données techniques

Cutting hole	6.50" (165.1 mm)
Beam Angle	60° ± 1/2
Color Temperature	3000k / 4000k
Mounting Plate	AMP600/MPHB600
CRI	>80
Voltage	120-277V
Dimmable	0-10V DIM
Volt - Special Order	120V
Dimmable	120V - DIM
Bulb Life	45,000hrs
Light Output - Lumen	1660LM
Operating Temperature	-20°C + 40°C
Amps	0.1682