

LED Gimbal



LED Gimbal Downlights are easy to install and allow you to direct the light where needed! The interchangeable trims offered in a variety of shapes, sizes and finishes, give you many options to choose from. Whether in new construction or in retrofit applications, the module and trim combination will fit any application!

- Small aperture designed for a sleek and glare free result
- Light output comparable to a PAR20 halogen lamp
- 24° tilt and 360° module rotation to light any direction




LED Modules and Drivers


Order code	Description	Watts	Volts	Colour temp.	Lumen output	CRI	Life L70	Beam angle	CBCP	Finish	Traditional equivalent	Case qty
		(W)	(VAC)	(K)	(lm)		(hrs)	(°)	(cd)	(W)	(master)	
65981	LED/DL/GIMBAL/MOD/7W/30-22K/WH/STD	7	120	3 000-2 200	470	≥90	30 000	40	800	White	50	18
65982	LED/DL/GIMBAL/MOD/7W/30-22K/BN/STD	7	120	3 000-2 200	470	≥90	30 000	40	800	Brushed nickel	50	18
65420	LED/DL/GIMBAL/MOD/7W/30K/WH/STD	7	120	3 000	600	≥80	36 000	40	1 100	White	50	18
65422	LED/DL/GIMBAL/MOD/7W/30K/BN/STD	7	120	3 000	600	≥80	36 000	40	1 100	Brushed nickel	50	18
65421	LED/DL/GIMBAL/MOD/7W/40K/WH/STD	7	120	4 000	620	≥80	36 000	40	1 200	White	50	18
65423	LED/DL/GIMBAL/MOD/7W/40K/BN/STD	7	120	4 000	620	≥80	36 000	40	1 200	Brushed nickel	50	18

Trims


Order code	Description	Finish	Type	Case qty (master)
3" Round				
65432	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65433	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66230	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BK/STD	Black	Flat	96
65450	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/WH/STD	White	Curved	96
65451	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/BN/STD	Brushed nickel	Curved	96
3" Square				
65434	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65435	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66231	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96
4" Round				
65436	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65437	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66232	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96
4" Square				
65438	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65439	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66233	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96

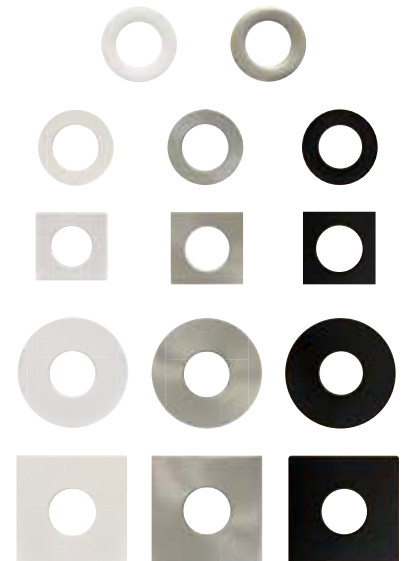

Dimensions

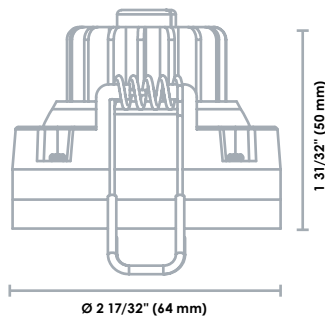


Module

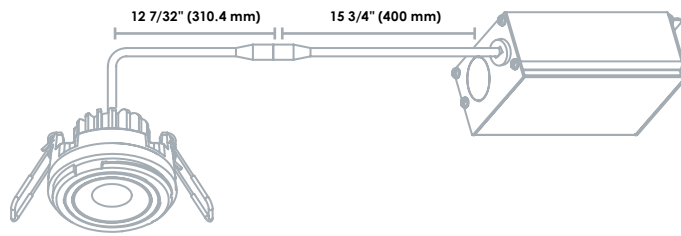


LED Module and Driver



Ø 2 3/4" (70 mm)

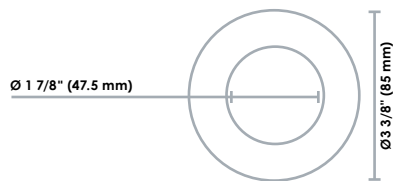


3" Trim

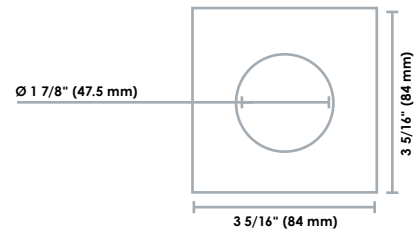


3" Trim



Ø 2 3/4" - 4 1/4" (70-108 mm)

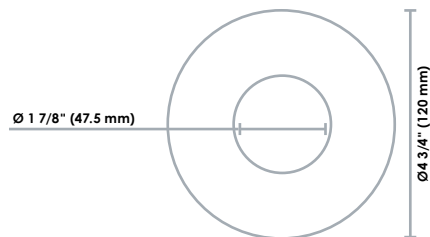


4" Trim

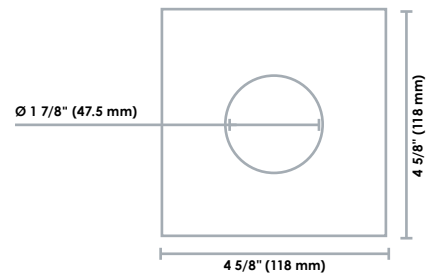

4" Trim

Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66020	ACC/MPLATE/2.75IN/SQR/STD	2 3/4	Square mounting plate	96
66021	ACC/MPLATE/2.75IN/ADJ/STD	2 3/4	Adjustable mounting plate	24
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96
66142	ACC/3/VAPOR BARRIER/STD	3 5/8	Vapor barrier extender	50

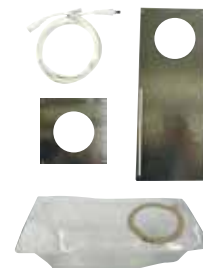

AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



5 YEARS WARRANTY



ETL Intertek



ENERGY STAR

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com