


# LED Vapor Tight



The Vapor Tight series is an enclosed luminaire that combines state-of-the-art LED technology with an IP rated vapor tight housing. This luminaire is protected against extreme temperatures, the intrusion of dust and jets of waters projected from any direction. Its durable construction provides protection against harsh environmental conditions and corrosion.


- Impact resistant polycarbonate construction
- Integrated durable gasket that seals the entire enclosure
- UV stabilized lens

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Case qty (master)
66196	LSV/N/35W/40K/120-277/DD1/FP/A1/STD	35	120-277	4 000	4 550	80	100 000	4
66876	LSV/N/35W/50K/120-277/DD1/FP/A1/STD	35	120-277	5 000	4 585	80	100 000	4
66197	LSV/N/40W/40K/120-277/DD1/FP/A1/STD	40	120-277	4 000	5 200	80	100 000	4
66877	LSV/N/40W/50K/120-277/DD1/FP/A1/STD	40	120-277	5 000	5 240	80	100 000	4
67075	LVT4/120-277/65W/40K/FR/A2/STD	65	120-277	4 000	8 450	80	100 000	4
67076	LVT4/120-277/65W/50K/FR/A2/STD	65	120-277	5 000	8 515	80	100 000	4
66198	LSV/N/35W/40K/347/DD1/FP/A1/STD	35	347	4 000	4 550	80	100 000	4
66199	LSV/N/52W/40K/347/DD1/FP/A1/STD	52	347	4 000	6 760	80	100 000	4
67077	LVT4/347/65W/40K/FR/A2/STD	65	347	4 000	8 580	80	100 000	4
67078	LVT4/347/65W/50K/FR/A2/STD	65	347	5 000	8 775	80	100 000	4

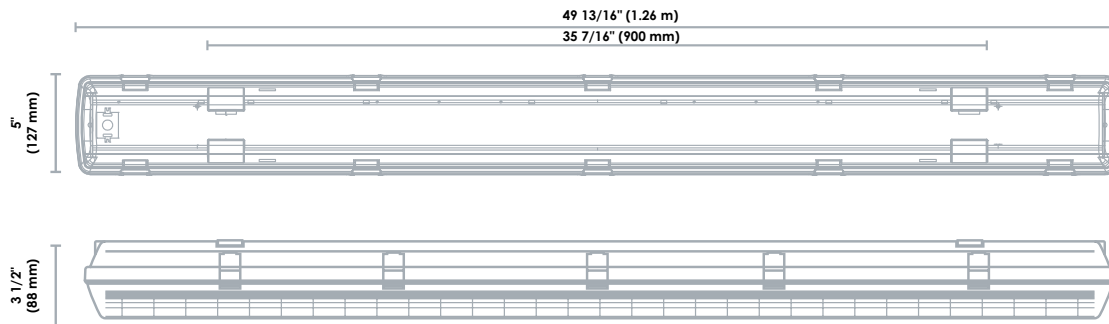

## Accessories

Order code	Description	Type	Compatible with
66878	LSV/N/LENS/FP/STD	Replacement Lens	All LSV/N and LVT4
67079	LVT4/ACC/STAINLESS STEEL CLIPS/STD	Stainless Steel Clips	All LSV/N and LVT4
67080 <sup>1</sup>	LVT4/ACC/PLASTIC CLIPS/STD	Plastic Clips	All LSV/N and LVT4
67341	LVT4/ACC/BACKET/STD	Mounting Bracket	All LSV/N and LVT4

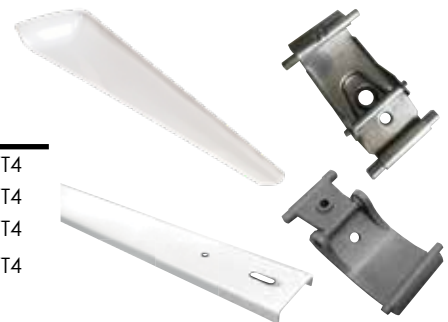

Lumen values are derived from photometric testing.  
For a complete list of compatible dimmers and DLC qualified products, please visit [www.standardpro.com](http://www.standardpro.com)  
<sup>1</sup> Non-stocked items, contact STANDARD for lead time and minimum order quantity.