



Attractive, dimmable LED alternative to popular incandescents.

A-Shape LED

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Benefits

- 12.5W and 8W A19 lamps are ENERGY STAR[®] qualified
- Long life properties-- lowers maintenance costs by reducing re-lamp frequency
- Will not fade colors, avoids inventory spoilage
- Contains no mercury
- Emits virtually no UV/IR light in the beam
- 3-year or 5-year limited warranty depending upon operating hours

Features

- 12.5W A19, 8W A19 and 17W A21 versions available
- Smooth dimming to 10% of full light levels*
- Remote phosphor (yellow) disappears when energized to create even, soft white light
- 25,000-hour rated average life⁺
- Instant-on light
- ^{*} Dimmable when using leading edge dimmers (see Philips Website: www.philips.com/ledtechguide for compatible leading edge dimmers.)
- ⁺ Rated average life based on engineering testing and probability analysis.

Application

- Ideal for decorative and ambient lighting in retail outlets, hotels, restaurants, multi-unit residences and government buildings.

A-Shape LED

Versions



E26 A19 Frosted



E26 A19 Frosted




E26 A21 Frosted



E26 A19 Frosted



E12 A15 Clear

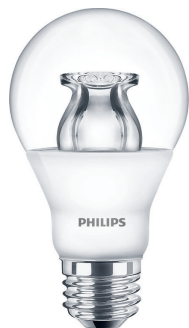

E26 A19 Clear



E26 A19 Frosted



E26 A19 Frosted



E26 A19 Frosted



E26 A19 Frosted



LEDbulb E26 A30 Frosted







LEDbulb E26 A35 Frosted



LEDbulb E26 A40 Frosted

A-Shape LED

Dimensional drawing

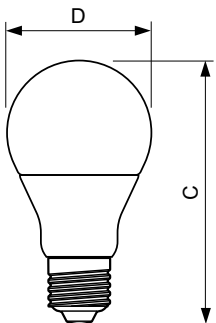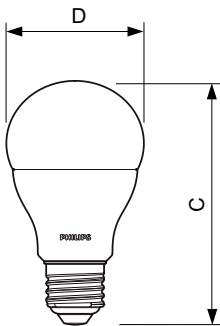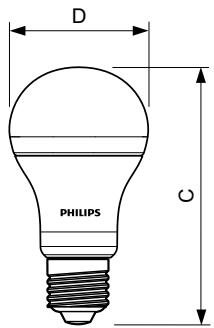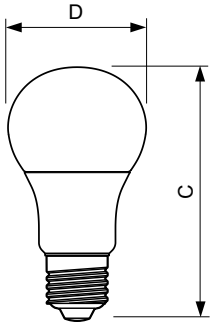

Product	D	C
5.5A19/LED/827/ND 120V 2PK/4	61 mm	107 mm
A19 8W 5000K E26	61.0 mm	107.4 mm
A19 8.5W 2700K E26	61 mm	107 mm
8A19/LED/850/ND 120V 2PK/4	61.0 mm	107.4 mm
5A19/LED/850/ND 120V 1PK/6	61 mm	107 mm
8.5A19/LED/827/ND 120V 2PK/4	61 mm	107 mm
5.5A19/LED/827/ND 120V 1PK/6	61 mm	107 mm
18A21/LED/827 3WAY ND 120V	71.1 mm	134.6 mm
10.5A19/LED/827 ND 120V	61 mm	107 mm
BC8A19/LED/BLUE/ND 120V	61.0 mm	107 mm
5A19/LED/850/ND 120V 2PK/4	61 mm	107 mm
9.5A19/LED/850 ND 120V	61 mm	107 mm





Product	D	C
120V A19 E26 14.5W 2700K	61.0 mm	107.4 mm
A19 14W 5000K E26	61.0 mm	107.4 mm

Product	D	C
9A19/LED/830 DIM 120V	61.4 mm	109.8 mm
9A19/AMB/850 DIM 120V	61.4 mm	109.8 mm
9.5A19/AMB/822-827 DIM 120V	61.4 mm	109.8 mm
9.5A19/AMB/827/DIM 120V	61.4 mm	109.8 mm

Product	D	C
9A19/LED/850/ND SSDL 120V	61.0 mm	111 mm

A-Shape LED

Dimensional drawing

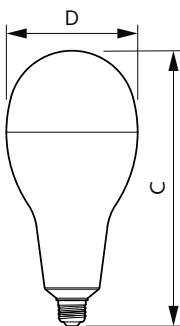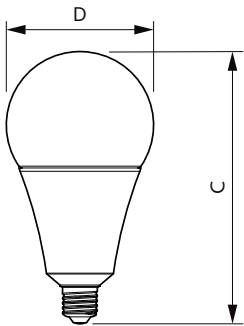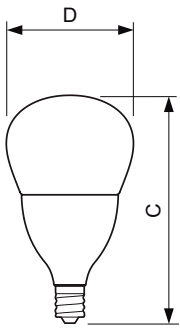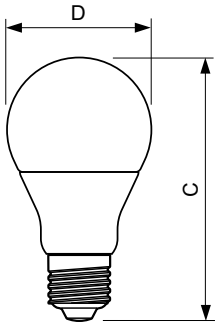

Product	D	C
9A19/LED/827-25-22/ND SSWG 120V	61.0 mm	111 mm
10A19/LED/827-22/CL/DIM 120V	62 mm	111 mm
6A19/LED/827-22/CL/DIM 120V	62 mm	111 mm
9.5A19/LED/827-50-22/ND SSCC 120V	61.0 mm	111 mm


Product	D	C
5.5A15/LED/827-22/E12/CL/DIM 120V	50 mm	91 mm

Product	D	C
24A35/LED/865/P/E26E39/ND 4/1FB	110 mm	200 mm

Product	D	C
42A40/LED/865/P/E26E39/ND 4/1FB	125 mm	265 mm

A-Shape LED

Dimensional drawing

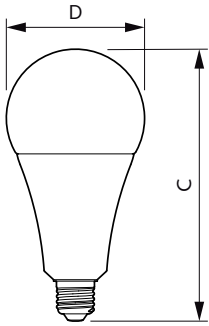

Operating and Electrical	
Voltage (Nom)	120 V
Light Technical	
Llmf At End Of Nominal Lifetime (Nom)	70 %

Product	D	C
20A30/LED/865/P/E26/ND 4/1FB	95 mm	185 mm

Approval and Application

Order Code	Full Product Name	Energy Consumption kWh/1000 h	Energy Efficiency Label (EEL)
455683	14.5A19/LED/827 ND 120V 6/1	14.5 kWh	-
455717	14A19/LED/850 ND 120V	14 kWh	-
455501	8.5A19/LED/827 ND 120V	8.5 kWh	-
462150	8.5A19/LED/827/ND 120V 2PK 4/2	-	-
455600	8A19/LED/850 ND 120V	8 kWh	-
462168	8A19/LED/850/ND 120V 2PK 4/2	8 kWh	-
460634	5.5A19/LED/827/ND 120V 6/1	-	-
462176	5.5A19/LED/827/ND 120V 2PK 4/2	-	-
460717	5A19/LED/850/ND 120V 6/1	-	-
462184	5A19/LED/850/ND 120V 2PK 4/2	-	-
462985	10.5A19/LED/827 ND 120V 6/1	-	-
463018	9.5A19/LED/850 ND 120V 6/1	-	-
459164	18A21/LED/827 3WAY ND 120V 6/1	-	-
455824	9.5A19/AMB/827-22/DIM 120V 6/1	-	-

Order Code	Full Product Name	Energy Consumption kWh/1000 h	Energy Efficiency Label (EEL)
459057	9A19/LED/830/DIM 120V 6/1	-	-
455881	9A19/AMB/850/DIM 120V 6/1	-	-
461269	9.5A19/AMB/827/DIM 120V 6/1	-	-
463983	5.5A15/LED/827-22/E12/CL/DIM 120V	-	-
462531	10A19/LED/827-22/CL/DIM 120V	10 kWh	-
462515	6A19/LED/827-22/CL/DIM 120V	6 kWh	-
463307	BC8A19/LED/BLUE/ND 120V 6/1	-	-
464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	-	Not applicable
464973	9A19/LED/850/ND SSDL 120V 6/1	-	Not applicable
464957	9.5A19/LED/827-50-22/ND SSSC 120V 6/1	-	Not applicable
479287	20A30/LED/865/P/E26/ND 4/1FB	-	-
479295	24A35/LED/865/P/E26E39/ND 4/1FB	-	-
479303	42A40/LED/865/P/E26E39/ND 4/1FB	-	-

Controls and Dimming

Order Code	Full Product Name	Dimmable
455683	14.5A19/LED/827 ND 120V 6/1	No
455717	14A19/LED/850 ND 120V	No
455501	8.5A19/LED/827 ND 120V	No
462150	8.5A19/LED/827/ND 120V 2PK 4/2	No
455600	8A19/LED/850 ND 120V	No
462168	8A19/LED/850/ND 120V 2PK 4/2	No
460634	5.5A19/LED/827/ND 120V 6/1	No
462176	5.5A19/LED/827/ND 120V 2PK 4/2	No
460717	5A19/LED/850/ND 120V 6/1	No

Order Code	Full Product Name	Dimmable
462184	5A19/LED/850/ND 120V 2PK 4/2	No
462985	10.5A19/LED/827 ND 120V 6/1	No
463018	9.5A19/LED/850 ND 120V 6/1	No
459164	18A21/LED/827 3WAY ND 120V 6/1	No
455824	9.5A19/AMB/827-22/DIM 120V 6/1	Yes
459057	9A19/LED/830/DIM 120V 6/1	Yes
455881	9A19/AMB/850/DIM 120V 6/1	Yes
461269	9.5A19/AMB/827/DIM 120V 6/1	Yes
463983	5.5A15/LED/827-22/E12/CL/DIM 120V	Yes

A-Shape LED

Order Code	Full Product Name	Dimmable
462531	10A19/LED/827-22/CL/DIM 120V	Yes
462515	6A19/LED/827-22/CL/DIM 120V	Yes
463307	BC8A19/LED/BLUE/ND 120V 6/1	No
464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	No
464973	9A19/LED/850/ND SSDL 120V 6/1	No

Order Code	Full Product Name	Dimmable
464957	9.5A19/LED/827-50-22/ND SSCC 120V 6/1	No
479287	20A30/LED/865/P/E26/ND 4/1FB	No
479295	24A35/LED/865/P/E26E39/ND 4/1FB	No
479303	42A40/LED/865/P/E26E39/ND 4/1FB	No

Operating and Electrical

Order Code	Full Product Name	Input Frequency	Wattage Equivalent	Power (Rated) (Nom)	Starting Time (Nom)
455683	14.5A19/LED/827 ND 120V 6/1	60 Hz	100 W	14.5 W	0.5 s
455717	14A19/LED/850 ND 120V	60 Hz	100 W	14 W	0.5 s
455501	8.5A19/LED/827 ND 120V	60 Hz	60 W	8.5 W	0.5 s
462150	8.5A19/LED/827/ND 120V 2PK 4/2	60 Hz	60 W	8.5 W	0.5 s
455600	8A19/LED/850 ND 120V	60 Hz	60 W	8 W	0.5 s
462168	8A19/LED/850/ND 120V 2PK 4/2	60 Hz	60 W	8 W	0.5 s
460634	5.5A19/LED/827/ND 120V 6/1	60 Hz	40 W	5.5 W	0.5 s
462176	5.5A19/LED/827/ND 120V 2PK 4/2	60 Hz	40 W	5.5 W	0.5 s
460717	5A19/LED/850/ND 120V 6/1	60 Hz	40 W	5 W	0.5 s
462184	5A19/LED/850/ND 120V 2PK 4/2	60 Hz	40 W	5 W	0.5 s
462985	10.5A19/LED/827 ND 120V 6/1	60 Hz	75 W	10.5 W	0.5 s
463018	9.5A19/LED/850 ND 120V 6/1	60 Hz	75 W	9.5 W	0.5 s
459164	18A21/LED/827 3WAY ND 120V 6/1	60 Hz	100 W	18 W	0.5 s
455824	9.5A19/AMB/827-22/DIM 120V 6/1	60 Hz	60 W	9.5 W	0.5 s
459057	9A19/LED/830/DIM 120V 6/1	60 Hz	60 W	9 W	0.5 s

Order Code	Full Product Name	Input Frequency	Wattage Equivalent	Power (Rated) (Nom)	Starting Time (Nom)
455881	9A19/AMB/850/DIM 120V 6/1	60 Hz	60 W	9 W	0.5 s
461269	9.5A19/AMB/827/DIM 120V 6/1	60 Hz	60 W	9.5 W	0.5 s
463983	5.5A15/LED/827-22/E12/CL/DIM 120V	60 Hz	40 W	5.5 W	0.5 s
462531	10A19/LED/827-22/CL/DIM 120V	60 Hz	60 W	10 W	0.5 s
462515	6A19/LED/827-22/CL/DIM 120V	60 Hz	40 W	6 W	0.5 s
463307	BC8A19/LED/BLUE/ND 120V 6/1	60 Hz	60 W	8 W	0.5 s
464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	50 to 60 Hz	60 W	-	0.5 s
464973	9A19/LED/850/ND SSDL 120V 6/1	50 to 60 Hz	60 W	-	0.5 s
464957	9.5A19/LED/827-50-22/ND SSCC 120V 6/1	60 Hz	60 W	9.5 W	0.5 s
479287	20A30/LED/865/P/E26/ND 4/1FB	60 Hz	160 W	20 W	1 s
479295	24A35/LED/865/P/E26E39/ND 4/1FB	60 Hz	200 W	24 W	1 s
479303	42A40/LED/865/P/E26E39/ND 4/1FB	60 Hz	300 W	42 W	1 s

General Information

Order Code	Full Product Name	Cap-Base	Nominal Lifetime (Nom)	Rated Lifetime (Hours)	Switching Cycle
455683	14.5A19/LED/827 ND 120V 6/1	E26	10950 h	10950 h	50000X
455717	14A19/LED/850 ND 120V	E26	10950 h	10950 h	50000X
455501	8.5A19/LED/827 ND 120V	E26	10950 h	10950 h	50000X

Order Code	Full Product Name	Cap-Base	Nominal Lifetime (Nom)	Rated Lifetime (Hours)	Switching Cycle
462150	8.5A19/LED/827/ND 120V 2PK 4/2	E26	10950 h	10950 h	50000X
455600	8A19/LED/850 ND 120V	E26	10950 h	10950 h	50000X

A-Shape LED

Order Code	Full Product Name	Cap-Base	Nominal Lifetime (Nom)	Rated Lifetime (Hours)	Switching Cycle
462168	8A19/LED/850/ND 120V 2PK 4/2	E26	10950 h	10950 h	50000X
460634	5.5A19/LED/827/ND 120V 6/1	E26	10950 h	10950 h	50000X
462176	5.5A19/LED/827/ND 120V 2PK 4/2	E26	10950 h	10950 h	50000X
460717	5A19/LED/850/ND 120V 6/1	E26	10950 h	10950 h	50000X
462184	5A19/LED/850/ND 120V 2PK 4/2	E26	10950 h	10950 h	50000X
462985	10.5A19/LED/827 ND 120V 6/1	E26	10950 h	10950 h	50000X
463018	9.5A19/LED/850 ND 120V 6/1	E26	10950 h	10950 h	50000X
459164	18A21/LED/827 3WAY ND 120V 6/1	E26	25000 h	25000 h	50000X
455824	9.5A19/AMB/827-22/DIM 120V 6/1	E26	25000 h	25000 h	50000X
459057	9A19/LED/830/DIM 120V 6/1	E26	25000 h	25000 h	50000X
455881	9A19/AMB/850/DIM 120V 6/1	E26	25000 h	25000 h	50000X
461269	9.5A19/AMB/827/DIM 120V 6/1	E26	25000 h	25000 h	50000X

Order Code	Full Product Name	Cap-Base	Nominal Lifetime (Nom)	Rated Lifetime (Hours)	Switching Cycle
463983	5.5A15/LED/827-22/E12/CL/DIM 120V	E12	25000 h	25000 h	50000X
462531	10A19/LED/827-22/CL/DIM 120V	E26	25000 h	25000 h	50000X
462515	6A19/LED/827-22/CL/DIM 120V	E26	25000 h	25000 h	50000X
463307	BC8A19/LED/BLUE/ND 120V 6/1	E26	10950 h	10950 h	50000X
464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	E26	15000 h	15000 h	100000X
464973	9A19/LED/850/ND SSDL 120V 6/1	E26	15000 h	15000 h	100000X
464957	9.5A19/LED/827-50-22/ND SSSC 120V 6/1	E26	15000 h	15000 h	100000X
479287	20A30/LED/865/P/E26/ND 4/1FB	E26	25000 h	25000 h	50000X
479295	24A35/LED/865/P/E26E39/ND 4/1FB	E26	25000 h	25000 h	50000X
479303	42A40/LED/865/P/E26E39/ND 4/1FB	E26	25000 h	25000 h	50000X

Light Technical

Order Code	Full Product Name	Beam Angle (Nom)	Color Code	Correlated Color Temperature (Nom)	Color Rendering Index (Nom)	Luminous Flux (Nom)	Luminous Flux (Rated)
455683	14.5A19/LED/827 ND 120V 6/1	-	827	2700 K	80	1500 lm	1500 lm
455717	14A19/LED/850 ND 120V	-	850	5000 K	80	1500 lm	1500 lm
455501	8.5A19/LED/827 ND 120V	-	827	2700 K	80	800 lm	800 lm
462150	8.5A19/LED/827/ND 120V 2PK 4/2	-	827	2700 K	80	800 lm	800 lm
455600	8A19/LED/850 ND 120V	-	850	5000 K	80	800 lm	800 lm
462168	8A19/LED/850/ND 120V 2PK 4/2	-	850	5000 K	80	800 lm	800 lm
460634	5.5A19/LED/827/ND 120V 6/1	-	827	2700 K	80	450 lm	450 lm
462176	5.5A19/LED/827/ND 120V 2PK 4/2	-	827	2700 K	80	450 lm	450 lm
460717	5A19/LED/850/ND 120V 6/1	-	850	5000 K	80	450 lm	450 lm
462184	5A19/LED/850/ND 120V 2PK 4/2	-	850	5000 K	80	450 lm	450 lm
462985	10.5A19/LED/827 ND 120V 6/1	-	827	2700 K	80	1000 lm	1000 lm
463018	9.5A19/LED/850 ND 120V 6/1	-	850	5000 K	80	1000 lm	1000 lm
459164	18A21/LED/827 3WAY ND 120V 6/1	-	827	2700 K	80	1600 lm	1600 lm
455824	9.5A19/AMB/827-22/DIM 120V 6/1	-	822-827	2200-2700 K	80	800 lm	800 lm
459057	9A19/LED/830/DIM 120V 6/1	-	830	3000 K	80	800 lm	800 lm
455881	9A19/AMB/850/DIM 120V 6/1	-	850	5000 K	80	800 lm	800 lm
461269	9.5A19/AMB/827/DIM 120V 6/1	-	827	2700 K	80	800 lm	800 lm
463983	5.5A15/LED/827-22/E12/CL/DIM 120V	-	822-827	2200-2700 K	80	450 lm	450 lm
462531	10A19/LED/827-22/CL/DIM 120V	-	822-827	2200-2700 K	80	800 lm	800 lm
462515	6A19/LED/827-22/CL/DIM 120V	-	822-827	2200-2700 K	80	480 lm	480 lm
463307	BC8A19/LED/BLUE/ND 120V 6/1	-	-	-	-	-	-
464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	300 °	827/825/822	-	80	-	-

A-Shape LED

Order Code	Full Product Name	Beam Angle	Correlated Color Temperature		Color Rendering		Luminous Flux (Rated)	
		(Nom)	Color Code	(Nom)	Index (Nom)	Luminous Flux (Nom)		
464973	9A19/LED/850/ND SSDL 120V 6/1	300 °	850	5000 K	80	-	-	
464957	9.5A19/LED/827-50-22/ND SSCC 120V 6/1	-	827/850/822	-	80	800 lm	-	
479287	20A30/LED/865/P/E26/ND 4/1FB	150 °	865	6500 K	80	2300 lm	2300 lm	
479295	24A35/LED/865/P/E26E39/ND 4/1FB	150 °	865	6500 K	80	3000 lm	3000 lm	
479303	42A40/LED/865/P/E26E39/ND 4/1FB	150 °	865	6500 K	80	5000 lm	5000 lm	

Mechanical and Housing













Order Code	Full Product Name	Bulb Finish	Bulb Shape	Order Code	Full Product Name	Bulb Finish	Bulb Shape
455683	14.5A19/LED/827 ND 120V 6/1	Frosted (FR)	A19 (A19)	459057	9A19/LED/830/DIM 120V 6/1	Frosted (FR)	A19 (A19)
455717	14A19/LED/850 ND 120V	Frosted (FR)	A19 (A19)	455881	9A19/AMB/850/DIM 120V 6/1	Frosted (FR)	A19 (A19)
455501	8.5A19/LED/827 ND 120V	Frosted (FR)	A19 (A19)	461269	9.5A19/AMB/827/DIM 120V 6/1	Frosted (FR)	A19 (A19)
462150	8.5A19/LED/827/ND 120V 2PK 4/2	Frosted (FR)	A19 (A19)	463983	5.5A15/LED/827-22/E12/CL/DIM 120V	Clear (CL)	A15
455600	8A19/LED/850 ND 120V	Frosted (FR)	A19 (A19)	462531	10A19/LED/827-22/CL/DIM 120V	Clear (CL)	A19 (A19)
462168	8A19/LED/850/ND 120V 2PK 4/2	Frosted (FR)	A19 (A19)	462515	6A19/LED/827-22/CL/DIM 120V	Clear (CL)	A19 (A19)
460634	5.5A19/LED/827/ND 120V 6/1	Frosted (FR)	A19 (A19)	463307	BC8A19/LED/BLUE/ND 120V 6/1	Frosted	A19 (A19)
462176	5.5A19/LED/827/ND 120V 2PK 4/2	Frosted (FR)	A19 (A19)	464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	Frosted (FR)	A19 (A19)
460717	5A19/LED/850/ND 120V 6/1	Frosted (FR)	A19 (A19)	464973	9A19/LED/850/ND SSDL 120V 6/1	Frosted (FR)	A19 (A19)
462184	5A19/LED/850/ND 120V 2PK 4/2	Frosted (FR)	A19 (A19)	464957	9.5A19/LED/827-50-22/ND SSCC 120V 6/1	Frosted (FR)	A19 (A19)
462985	10.5A19/LED/827 ND 120V 6/1	Frosted (FR)	A19 (A19)	479287	20A30/LED/865/P/E26/ND 4/1FB	Frosted (FR)	A30
463018	9.5A19/LED/850 ND 120V 6/1	Frosted (FR)	A19 (A19)	479295	24A35/LED/865/P/E26E39/ND 4/1FB	Frosted (FR)	A35
459164	18A21/LED/827 3WAY ND 120V 6/1	Frosted (FR)	A21 (A21)	479303	42A40/LED/865/P/E26E39/ND 4/1FB	Frosted (FR)	A40
455824	9.5A19/AMB/827-22/DIM 120V 6/1	Frosted (FR)	A19 (A19)				

Temperature

Order Code	Full Product Name	T-Case Maximum (Nom)	Order Code	Full Product Name	T-Case Maximum (Nom)
455683	14.5A19/LED/827 ND 120V 6/1	95 °C	459057	9A19/LED/830/DIM 120V 6/1	95 °C
455717	14A19/LED/850 ND 120V	90 °C	455881	9A19/AMB/850/DIM 120V 6/1	95 °C
455501	8.5A19/LED/827 ND 120V	100 °C	461269	9.5A19/AMB/827/DIM 120V 6/1	95 °C
462150	8.5A19/LED/827/ND 120V 2PK 4/2	100 °C	463983	5.5A15/LED/827-22/E12/CL/DIM 120V	90 °C
455600	8A19/LED/850 ND 120V	95 °C	462531	10A19/LED/827-22/CL/DIM 120V	95 °C
462168	8A19/LED/850/ND 120V 2PK 4/2	100 °C	462515	6A19/LED/827-22/CL/DIM 120V	85 °C
460634	5.5A19/LED/827/ND 120V 6/1	100 °C	463307	BC8A19/LED/BLUE/ND 120V 6/1	-
462176	5.5A19/LED/827/ND 120V 2PK 4/2	100 °C	464965	9A19/LED/827-25-22/ND SSWG 120V 6/1	80 °C
460717	5A19/LED/850/ND 120V 6/1	100 °C	464973	9A19/LED/850/ND SSDL 120V 6/1	80 °C
462184	5A19/LED/850/ND 120V 2PK 4/2	100 °C	464957	9.5A19/LED/827-50-22/ND SSCC 120V 6/1	89 °C
462985	10.5A19/LED/827 ND 120V 6/1	100 °C	479287	20A30/LED/865/P/E26/ND 4/1FB	85 °C
463018	9.5A19/LED/850 ND 120V 6/1	100 °C	479295	24A35/LED/865/P/E26E39/ND 4/1FB	85 °C
459164	18A21/LED/827 3WAY ND 120V 6/1	100 °C	479303	42A40/LED/865/P/E26E39/ND 4/1FB	85 °C
455824	9.5A19/AMB/827-22/DIM 120V 6/1	95 °C			










A-Shape LED

Light Distribution Diagrams

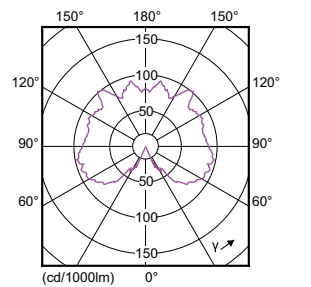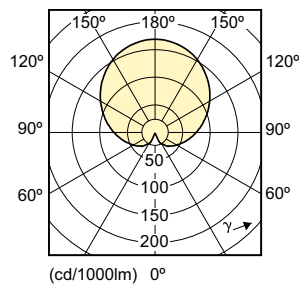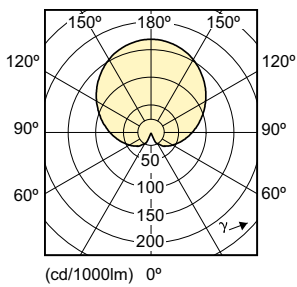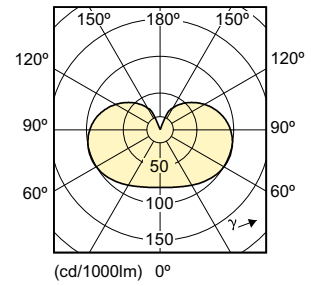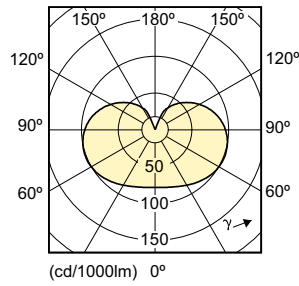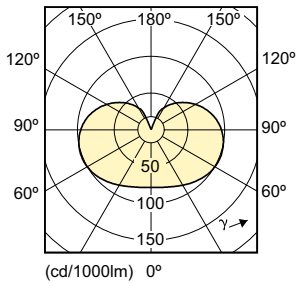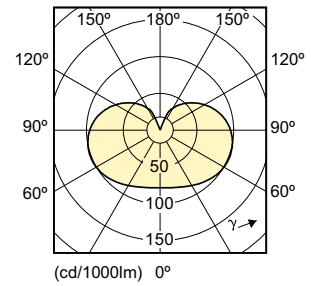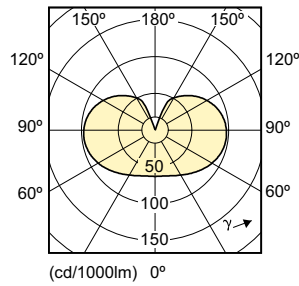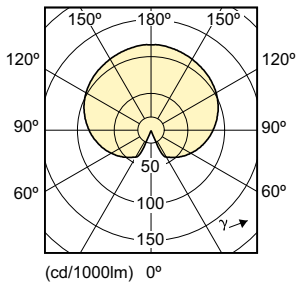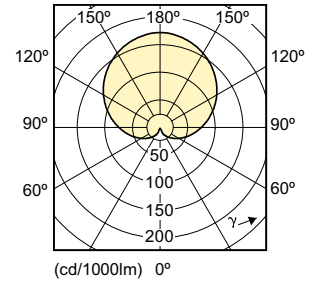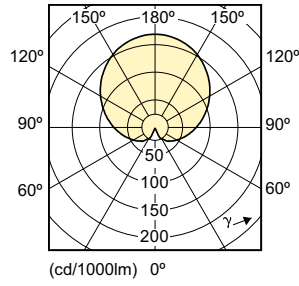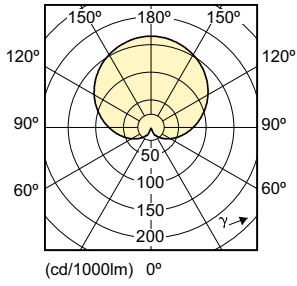

A-Shape LED

Light Distribution Diagrams

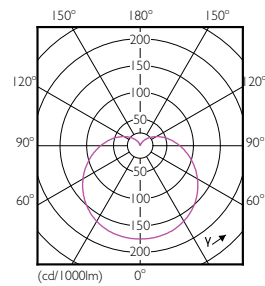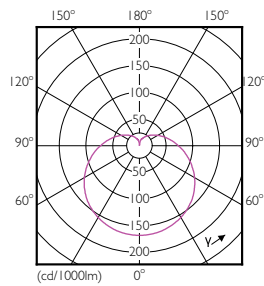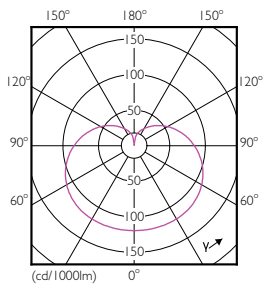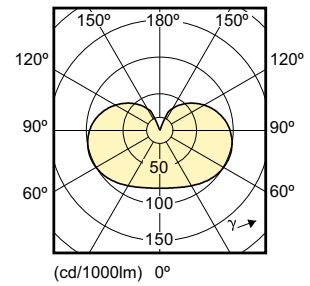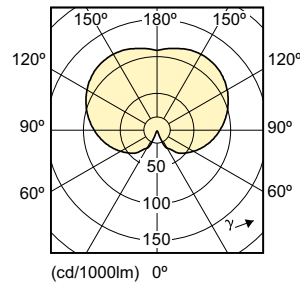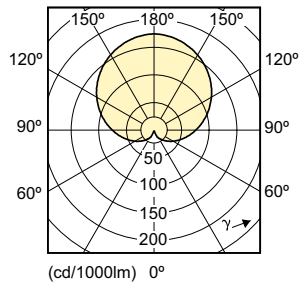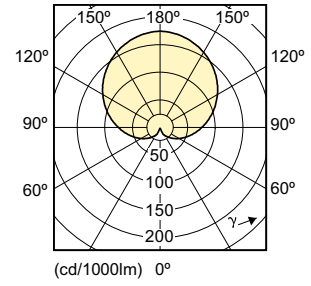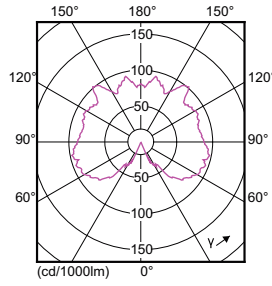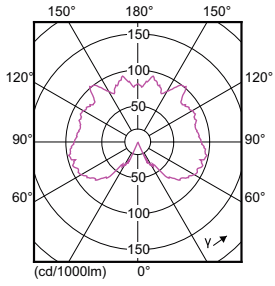

LEDbulb 20W A30 E26 865 15D ND

LEDbulb 24W A35 E26 865 15D ND

LEDbulb 42W A40 E26 865 15D ND

