



Nuheat
 Floor Warming Systems
 toll free 1 (800) 778-WARM (9276)
 fax (604) 529-4404



www.nuheat.com
 info@nuheat.com

Nuheat Standard Mat Sizes (110V)

Dimensions (inches)	Ohms	Amps	Watts	Model Number
40 x 27	134	0.8	90	F1006
40 x 32	113	1	107	F1008
40 x 40	91	1.2	133	F1010
40 x 48	76	1.5	160	F1012
48 x 24	126	0.9	96	F1206
48 x 30	101	1.1	120	F1208
48 x 36	84	1.3	144	F1209
48 x 48	63	1.7	192	F1212
60 x 24	101	1.1	120	F1506
60 x 30	81	1.4	150	F1508
60 x 36	67	1.6	180	F1509
60 x 42	58	1.9	210	F1510
60 x 48	50	2.2	240	F1512
60 x 60	40	2.7	300	F1515
72 x 24	84	1.3	144	F1806
72 x 30	67	1.6	180	F1808
72 x 36	56	2	216	F1809
72 x 42	48	2.3	252	F1810
72 x 48	42	2.6	288	F1812
72 x 60	34	3.3	360	F1815
72 x 72	28	3.9	432	F1818
84 x 24	72	1.5	168	F2106
84 x 30	58	1.9	210	F2108
84 x 36	48	2.3	252	F2109
84 x 42	41	2.7	294	F2110
84 x 48	36	3.1	336	F2112
84 x 60	29	3.8	420	F2115
84 x 72	24	4.6	504	F2118
84 x 84	21	5.3	588	F2121
96 x 24	63	1.7	192	F2506
96 x 30	50	2.2	240	F2508
96 x 36	42	2.6	288	F2509
96 x 42	36	3.1	336	F2510
96 x 48	32	3.5	384	F2512
96 x 60	25	4.4	480	F2515
96 x 72	21	5.2	576	F2518
96 x 84	18	6.1	672	F2521
96 x 96	16	7	768	F2525
108 x 24	56	2	216	F2706
108 x 30	45	2.5	270	F2708
108 x 36	37	2.9	324	F2709
108 x 42	32	3.4	378	F2710
108 x 48	28	3.9	432	F2712
108 x 60	22	4.9	540	F2715
108 x 72	19	5.9	648	F2718
108 x 84	16	6.9	756	F2721
108 x 96	14	7.9	864	F2725
108 x 108	12	8.8	972	F2727
118 x 24	51	2.1	236	F3006
118 x 30	41	2.7	295	F3008
118 x 36	34	3.2	354	F3009
118 x 42	29	3.8	413	F3010
118 x 48	26	4.3	472	F3012
118 x 60	20	5.4	590	F3015
118 x 72	17	6.4	708	F3018
118 x 84	15	7.5	826	F3021
118 x 96	13	8.6	944	F3025
118 x 108	11	9.7	1062	F3027
118 x 116	11	10.4	1141	F3030

Nuheat Standard Mat Sizes (220V)

Dimensions (inches)	Ohms	Amps	Watts	Model Number
60 x 36	269	0.8	180	G1509
60 x 42	230	1	210	G1510
60 x 48	202	1.1	240	G1512
60 x 60	161	1.4	300	G1515
72 x 30	269	0.8	180	G1808
72 x 36	224	1	216	G1809
72 x 42	192	1.1	252	G1810
72 x 48	168	1.3	288	G1812
72 x 60	134	1.6	360	G1815
72 x 72	112	2	432	G1818
84 x 24	288	0.8	168	G2106
84 x 30	230	1	210	G2108
84 x 36	192	1.1	252	G2109
84 x 42	165	1.3	294	G2110
84 x 48	144	1.5	336	G2112
84 x 60	115	1.9	420	G2115
84 x 72	96	2.3	504	G2118
84 x 84	82	2.7	588	G2121
96 x 24	252	0.9	192	G2506
96 x 30	202	1.1	240	G2508
96 x 36	168	1.3	288	G2509
96 x 42	144	1.5	336	G2510
96 x 48	126	1.7	384	G2512
96 x 60	101	2.2	480	G2515
96 x 72	84	2.6	576	G2518
96 x 84	72	3.1	672	G2521
96 x 96	63	3.5	768	G2525
108 x 24	224	1	216	G2706
108 x 30	179	1.2	270	G2708
108 x 36	149	1.5	324	G2709
108 x 42	128	1.7	378	G2710
108 x 48	112	2	432	G2712
108 x 60	90	2.5	540	G2715
108 x 72	75	2.9	648	G2718
108 x 84	64	3.4	756	G2721
108 x 96	56	3.9	864	G2725
108 x 108	50	4.4	972	G2727
118 x 24	205	1.1	236	G3006
118 x 30	164	1.3	295	G3008
118 x 36	137	1.6	354	G3009
118 x 42	117	1.9	413	G3010
118 x 48	103	2.1	472	G3012
118 x 60	82	2.7	590	G3015
118 x 72	68	3.2	708	G3018
118 x 84	59	3.8	826	G3021
118 x 96	51	4.3	944	G3025
118 x 108	46	4.8	1062	G3027
118 x 116	42	5.2	1141	G3030

Mat dimensions listed in inches.

Information subject to change at any time. For a complete list of up to date specifications please visit www.nuheat.com.

Nuheat Mat




Floor Warming Systems




Nuheat Mat

Pre-built like an electric blanket, Nuheat Mat is an electric floor warming system that brings soothing warmth to tile, stone, laminate and engineered wood floors. Thin heating wires are evenly spaced and embedded between two layers of durable fabric. The choice of professionals, Nuheat Mat is simple to install and radiates even heat with no cold spots.

A direct manufacturer's sales force, a technical services department and a full-time design team are part of Nuheat's superior customer service.

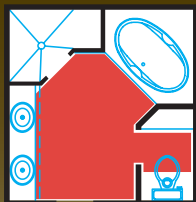

Custom mat layout

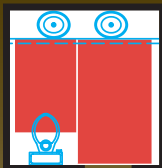

Standard mat layout

Installation Steps



Trowel thinset over sub-floor



Roll Nuheat Mat onto thinset



Trowel thinset and apply tile

*A professional tile setter installs Nuheat Mat onto the sub-floor.
A certified electrician connects the system to your household wiring.*

Fast Facts

Available in 110V and 220V

Over 60 standard mat sizes

Custom mats available for rooms with curves and angles

Only 1/8" thick; ideal for renovations and new construction projects

UL listed and CSA approved

Energy efficient (12 watts per sq ft); produces a floor temperature of 80°-90°F (27°-32°C) depending on type of application and heat loss

Industry leading 25-year warranty

Authorized distributors across North America; go to www.nuheat.com to find a distributor near you



Thermostats

Harmony

- Flush mounts behind a double-gang faceplate
- Floor sensing thermostat for tile, stone, laminate and engineered wood floors
- Programmable 7-day settings
- Backlit display
- Energy efficient
- Built-in Class A GFCI



MatComfort (NTG)

- Floor sensing thermostat for tile and stone floors
- Programmable 7-day settings
- Backlit display
- ENERGY STAR qualified
- Built-in Class A GFCI



MatComfort 82F

- Floor sensing thermostat for laminate and engineered wood surfaces
- Programmable 7-day settings
- Backlit display
- ENERGY STAR qualified
- Built-in Class A GFCI



Regulator

- The alternative to precision control and programmable features
- Heating indicator light
- Power selection dial
- Built-in Class A GFCI

