

Juno

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

**INCANDESCENT
LOUVERED
NIGHT LIGHT****INCANDESCENT LAMP
ICTC113****PRODUCT DESCRIPTION**

ICTC Housing designed for use in insulated or non-insulated areas. Refer to lamp data for correct lamp wattage.

PRODUCT SPECIFICATIONS

Lamp IC - One 25W A19 lamp • TC - One 40W A19 lamp.

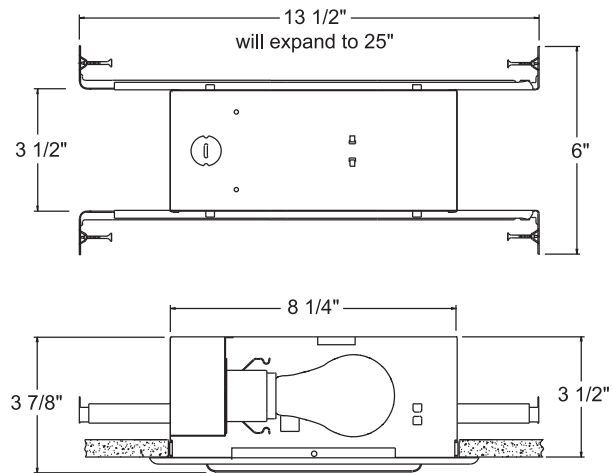
Socket Medium base porcelain with nickel-plated copper screw shell.

Trims Available in white baked enamel on steel • Fastens to housing with two torsion springs.

Labels UL listed for damp locations and IP • Product thermally protected against improper use of lamps • Union made • UL Listed/CSA certified.

Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

Product specifications subject to change without notice.

DIMENSIONS

8 3/4" X 3 3/4" WALL CUTOUT

INSTALLATION

Real Nail 3 Bar Hangers Telescoping, patent-pending Real Nail 3 system permits quick placement of housing anywhere within 24" O.C. joists or suspended ceilings • Integral T-bar notch and clip secures housing in suspended ceiling grid – no accessory clips required • 24" expansion stop allows quick placement of fixture in standard grid spacing • Bars scored in two locations for fast, clean breaking, allowing housing installation in tight applications • Bars captive to mounting frame • Edge-mounted for extra strength • Captive bugle-headed ring shank nail for quick one-step installation and easy removal with claw hammer for fixture relocation • Quick-Loc slot and oversized locking set screw lock fixture in position • Bar hanger foot contoured to align to bottom of construction joist • Alternate mounting holes included.

Junction Box Pre-wired junction compartment provided with (3) 1/2" knockouts, and ground wire, UL Listed, C-UL/CSA certified for No. 12 AWG daisy chain circuit connectors suitable for 90° C permitted in junction box • Junction compartment provided with removable access plate • Knockouts equipped with pryout slots.

Housing TC housing, 22-gauge white painted steel • 8 1/4" L x 3 1/2" H x 3 1/2" D.

 
 
PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating (max.)
ICTC113	120V	IC - 25W A19 / TC - 40W A19

INCANDESCENT LOUVERED NIGHT LIGHT

INCANDESCENT LAMP
ICTC113

COMPLETE FIXTURE/LAMP

	Cat. No.	Description	Lamp Rating
	104-WH	Diffuse Glass Lens, White Trim	IC - 25W A19, TC - 40W A19
	840-WH	Angled Louvers, White Trim	IC - 25W A19, TC - 40W A19

Trim Finish: WH - White.