



TRAC-MASTER®

Professional Series Halogen CONIX® LOW VOLTAGE

T406, T410 and T411

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

The sleek sculptured look and style of the Conix fixture is unparalleled in the industry. Its elegance is carried through the entire design for a fresh, contemporary appeal. Conix fixtures relamp from the front and have snap-in accessory holders. All can accommodate up to two accessories. Lampholders have integral horizontal rotation and vertical aiming locks.

PRODUCT SPECIFICATIONS

Construction Molded polycarbonate yoke • Die cast aluminum back housing
• Formed steel front housing.

Aiming Greater than 360° horizontal rotation eliminates aiming dead spots • 90° vertical aiming capability • Vertical aiming and horizontal rotation locking screws secure lampholder position during relamping cycles.

Transformer Must be ordered separately • Compatible with T537 or T538 12V electronic transformer for halogen lamps (D1.2.1) • Compatible with T537U universal 12V electronic transformer for LED or halogen lamps (D1.2.5) • Compatible with T539 12V electronic transformer for halogen lamps (D1.2.0) • Compatible with T542 or T543 12V magnetic transformer for LED or halogen lamps (D1.2.0).

Labels UL listed, CSA certified.

Product specifications subject to change without notice.



Low Voltage MR16

Lamp 12V, 50W maximum MR16 GU5.3/GX5.3 bi-pin.


Socket Ceramic bi-pin.

| Catalog Number | Finish | Lamp |
|----------------|--------|---------------|
| T406WH | White | 50W MR16 max. |
| T406BL | Black | 50W MR16 max. |
| T406SL | Silver | 50W MR16 max. |


ACCESSORIES

| Cat. No. | Description | Cat. No. | Description | Cat. No. | Description |
|----------|-----------------------|----------|--------------------|----------|-----------------|
| T557 | Prismatic Spread Lens | T559 | Linear Spread Lens | T551-5 | Color Filters |
| T5501-18 | Dichroic Lenses | T5520 | Diffusion Lens | T5521 | Uniformity Lens |
| T5522 | UV Filter | T5559BL | Hexcell Louver | | |


See Specification sheet [D1.2.2](#) for details.

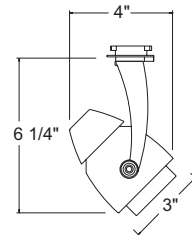

T537, T537U

 

T538

 

Low Voltage PAR36

Lamp 12V, 50W maximum PAR36 with screw terminals.


Socket Screw terminals.

| Catalog Number | Finish | Lamp |
|----------------|--------|----------------|
| T410WH | White | 50W PAR36 max. |
| T410BL | Black | 50W PAR36 max. |
| T410SL | Silver | 50W PAR36 max. |


ACCESSORIES

| Cat. No. | Description | Cat. No. | Description | Cat. No. | Description |
|----------|-------------------------|----------|-----------------------|----------|--------------------|
| T571-6 | Color Filters | T579BL | Cube Cell Louver | T5721 | Uniformity Lens |
| T5722 | UV Filter | T5777 | Prismatic Spread Lens | T5778 | Linear Spread Lens |
| T5718 | Color Correction Filter | | | | |


See specification sheet [D1.2.2](#) for details.

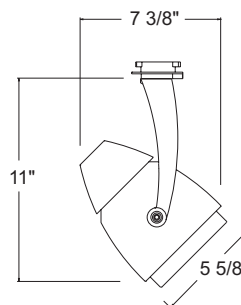

T537, T537U

 

T538

 

TRAC-MASTER®

Professional Series Halogen

CONIX® LOW VOLTAGE

T406, T410 and T411

Low Voltage AR111

Lamp 12V, 75W maximum AR111 with screw terminals.

Socket Screw terminals.

Lens Glass lens included with each lampholder.

| Catalog Number | Finish | Lamp |
|----------------|--------|----------------|
| T411WH | White | 75W AR111 max. |
| T411BL | Black | 75W AR111 max. |
| T411SL | Silver | 75W AR111 max. |

ACCESSORIES

| Cat. No. | Description | Cat. No. | Description | Cat. No. | Description |
|----------|-------------------------|----------|-----------------------|----------|--------------------|
| T571-6 | Color Filters | T579BL | Cube Cell Louver | T5721 | Uniformity Lens |
| T5722 | UV Filter | T5777 | Prismatic Spread Lens | T5778 | Linear Spread Lens |
| T5718 | Color Correction Filter | | | | |

See specification sheet [D1.2.2](#) for details.

