



SLOPE CEILING TC REMODEL HOUSING

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

STANDARD SLOPE:

2/12 to 6/12 PITCH (9° to 27°)

INCANDESCENT LAMPS

TC926R

PRODUCT DESCRIPTION

Slope ceiling TC Remodel Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in ceiling from below • Secures in place with factory supplied remodel clips • Designed for use in non-insulated areas • If installed where insulation is present, the insulation must be pulled back 3" from all sides of the TC housing.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected – see reverse.

Socket Medium base porcelain with nickel-plated copper screw shell • Adjustable to position lamp perpendicular to floor.



Trims Trim selection shown on reverse.

Labels U.L. listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps or insulation • Union made • UL Listed/CSA certified • Trim No. 610 is wet location approved for covered ceiling applications.

Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

Product specifications subject to change without notice.

DIMENSIONS

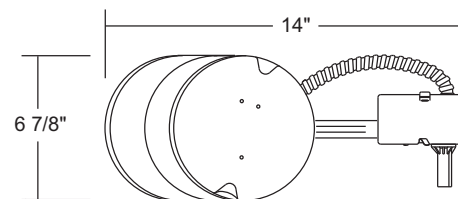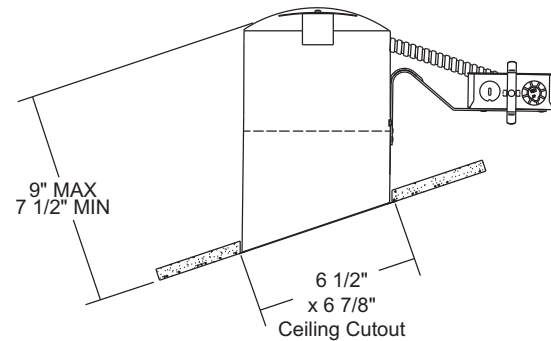

INSTALLATION

Junction Box Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (4) ½" knockouts, (4) Non-metallic sheathed cable connectors and ground wire • Knockouts equipped with pryout slots.

Housing TC housing, 22-gauge white painted steel with aluminum cap • Housing is vertically adjustable to accommodate up to a 1" ceiling thickness • Designed to fit 2x8 or 2x10 construction.

PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating (max.)
TC926R	120V	A19/MR16/BR30/R30/PAR30/PAR30L/PAR38

SLOPE CEILING TC REMODEL HOUSING







STANDARD SLOPE:

2/12 to 6/12 PITCH (9° to 27°)

INCANDESCENT LAMPS

TC926R

TRIMS/LAMPS

	Cat. No.	Description	Max. Lamp Rating
	610B-WH ◆ 610W-WH ◆	Lensed Abalite Black Baffle Lensed Abalite White Baffle	75W A19, 75W PAR30
	612C-WH 612G-WH 612B-WH 612HZ-WH 612HZ-SC 612W-WH 612WHZ-WH 612WHZ-ABZ	Multiplier Cone - Clear Alzak® Multiplier Cone - Gold Alzak® Multiplier Cone - Black Alzak® Multiplier Cone - Haze Multiplier Cone - Haze Multiplier Cone - White Multiplier Cone - Wheat Haze Multiplier Cone - Wheat Haze	75W PAR30, 150W PAR38, 85W BR30
	614B-WH 614B-SC 614B-ABZ 614B-BL 614W-WH	Downlight with Black Baffle Downlight with Black Baffle Downlight with Black Baffle Downlight with Black Baffle Downlight with White Baffle	150W PAR38
	616B-WH 616W-WH	Black Cylinder Spotlight with Black Baffle White Cylinder Spotlight with White Baffle	60W PAR16
	617W-WH	White Spotlight with White Baffle	50W MR16 supplied with magnetic transformer
	619B-WH 619W-WH	Eyeball in Black Baffle Eyeball in White Baffle	85W BR30

Trim Size: 7⁵/₈" O.D. (except Cat. Nos. 612 and 614 - 7³/₈" O.D.).

Trim Finish: ABZ - Classic Aged Bronze, BL - Black, GP - Graphite,

PW - Plastic White (Polycarbonate material shower trim), SC - Satin Chrome, SL - Silver, WH - White.

◆ UL Listed for use in wet location.



1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925
220 Chrysler Drive • Brampton, Ontario • Canada L6S 6B6 • Phone (905) 792-7335 • Fax (905) 792-0064
Visit us at www.junolightinggroup.com

Printed in U.S.A. ©2009 Juno Lighting, LLC.