

JUNO[®]**TRAC-MASTER**[®]

Avant Garde

WIREFORM[®] SERIES**T430, T431, T433, T435 and T437**

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

Specially designed for halogen lamps. This high-styled, exposed lamp design provides a strong hi-tech statement.

Construction Square steel wire.

Aiming 90° vertical aiming capability and 358° rotation • Two locking screws provided.

Labels UL listed • CSA certified • Union made • Assembled in U.S.A.

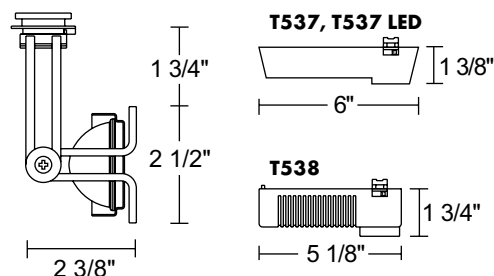
Specifications subject to change without notice.

**Low Voltage MR16**

Socket Ceramic bi-pin.

Transformer Must be ordered separately • Compatible with T537 or T538 12V electronic transformer for halogen lamps (D1.2.1) • Compatible with T537 LED universal 12V electronic transformer for LED or halogen lamps (D1.2.1) • Compatible with T539 12V electronic transformer for halogen lamps (D1.2.0) • Compatible with T543 12V magnetic transformer for LED or halogen lamps (D1.2.0).

Catalog Number	Description	Finish	Lamp
T430 WH	Wireform	White	75W MR16 max.
T430 BL	Wireform	Black	75W MR16 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description
HCLBL 175	Hexagonal Cell Louver - Black	UVF 175	UV Filter
CGF 175	Color Glass Filter	SOLITE 175	Uniformity Lens (Solite)
DCCF 175	Dichroic Color Correction Filter	PRISM 175	Prismatic Spread Glass Lens
DGF 175	Dichroic Glass Filter	LSPREAD 175	Linear Spread Glass Lens
DIFF 175	Diffusion Glass Lens	T74BL	1-3/4" Diameter Barn Doors - Black

See specification sheet D1.2.2 for details. Other accessories can be found on specification sheet D1.2.0.

TRAC-MASTER®

Avant Garde

WIREFORM® SERIES**T430, T431, T433, T435 and T437****Line Voltage PAR16**

Socket Medium base porcelain with nickel plated copper screw shell.

Juno Universal Trac Adapter Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track • Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.

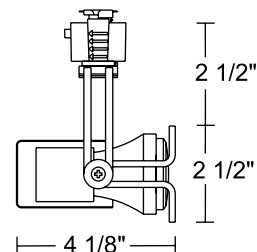
Alternate TEK Trac Adapter Compatible with Juno TEK trac system • System specific and assembled to trac fixture • Integrally polarized construction to prevent reverse installation – only allows insertion in proper orientation • Rotary circuit selector enables simple switching between circuits • Integral on/off switch enables individual fixtures to be switched for servicing.

Alternate GTYPE Trac Adapter Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type) • System specific and assembled to trac fixture • Consult factory for additional information.

Alternate HTYPE Trac Adapter Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type) • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Alternate LTYPE Trac Adapter Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Accessories T74BL Barn Doors • See specification sheet [D1.2.2](#) for details.



Catalog Number	Description	Finish	Lamp
T431 WH	Wireform w/Universal Trac Adapter	White	60W PAR16 max.
T431 BL	Wireform w/Universal Trac Adapter	Black	60W PAR16 max.
T431 SL	Wireform w/Universal Trac Adapter	Silver	60W PAR16 max.
T431 TEK WH	Wireform w/TEK Trac Adapter	White	60W PAR16 max.
T431 TEK BL	Wireform w/TEK Trac Adapter	Black	60W PAR16 max.
T431 TEK SL	Wireform w/TEK Trac Adapter	Silver	60W PAR16 max.
T431 GTYPE WH	Wireform w/G-Type Trac Adapter	White	60W PAR16 max.
T431 GTYPE BL	Wireform w/G-Type Trac Adapter	Black	60W PAR16 max.
T431 GTYPE SL	Wireform w/G-Type Trac Adapter	Silver	60W PAR16 max.
T431 HTYPE WH	Wireform w/H-Type Trac Adapter	White	60W PAR16 max.
T431 HTYPE BL	Wireform w/H-Type Trac Adapter	Black	60W PAR16 max.
T431 HTYPE SL	Wireform w/H-Type Trac Adapter	Silver	60W PAR16 max.
T431 LTYPE WH	Wireform w/L-Type Trac Adapter	White	60W PAR16 max.
T431 LTYPE BL	Wireform w/L-Type Trac Adapter	Black	60W PAR16 max.
T431 LTYPE SL	Wireform w/L-Type Trac Adapter	Silver	60W PAR16 max.

Mounting accessories can be found on specification sheet [D1.2.0](#).

ConTech is a registered trademark of ConTech Lighting.

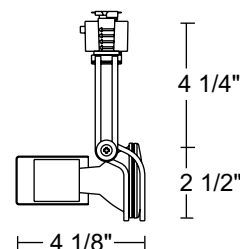


TRAC-MASTER®

Avant Garde

WIREFORM® SERIES**T430, T431, T433, T435 and T437****Line Voltage PAR20****Socket** Medium base porcelain with nickel plated copper screw shell.**Adapters** Refer to **T431**.

Catalog Number	Description	Finish	Lamp
T433 WH	Wireform w/Universal Trac Adapter	White	50W PAR20 max.
T433 BL	Wireform w/Universal Trac Adapter	Black	50W PAR20 max.
T433 SC	Wireform w/Universal Trac Adapter	Satin Chrome	50W PAR20 max.
T433 SL	Wireform w/Universal Trac Adapter	Silver	50W PAR20 max.
T433 TEK WH	Wireform w/TEK Trac Adapter	White	50W PAR20 max.
T433 TEK BL	Wireform w/TEK Trac Adapter	Black	50W PAR20 max.
T433 TEK SC	Wireform w/TEK Trac Adapter	Satin Chrome	50W PAR20 max.
T433 TEK SL	Wireform w/TEK Trac Adapter	Silver	50W PAR20 max.
T433 GTYPE WH	Wireform w/G-Type Trac Adapter	White	50W PAR20 max.
T433 GTYPE BL	Wireform w/G-Type Trac Adapter	Black	50W PAR20 max.
T433 GTYPE SC	Wireform w/G-Type Trac Adapter	Satin Chrome	50W PAR20 max.
T433 GTYPE SL	Wireform w/G-Type Trac Adapter	Silver	50W PAR20 max.
T433 HTYPE WH	Wireform w/H-Type Trac Adapter	White	50W PAR20 max.
T433 HTYPE BL	Wireform w/H-Type Trac Adapter	Black	50W PAR20 max.
T433 HTYPE SC	Wireform w/H-Type Trac Adapter	Satin Chrome	50W PAR20 max.
T433 HTYPE SL	Wireform w/H-Type Trac Adapter	Silver	50W PAR20 max.
T433 LTYPE WH	Wireform w/L-Type Trac Adapter	White	50W PAR20 max.
T433 LTYPE BL	Wireform w/L-Type Trac Adapter	Black	50W PAR20 max.
T433 LTYPE SC	Wireform w/L-Type Trac Adapter	Satin Chrome	50W PAR20 max.
T433 LTYPE SL	Wireform w/L-Type Trac Adapter	Silver	50W PAR20 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description
HCLBL 375	Hexcell Louver - Black	UVF 375	UV Filter
CCLBL 375	Cube Cell Louver - Black	SOLITE 375	Uniformity Lens (Solite)
SNOOTBL 375	Snoot - Black	PRISM 375	Prismatic Spread Glass Lens
CGF 375	Color Glass Filter	LSPREAD 375	Linear Spread Glass Lens
DCCF 375	Dichroic Color Correction Filter	TW75BL	Barn Doors - Black †
DGF 375	Dichroic Glass Filter	T40N¹	Monopoint
DIFF 375	Diffusion Glass Lens		

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Filters, lenses, snoot and louver require barn doors for installation.

Notes:

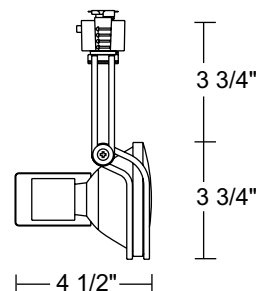
1 Add finish code to complete catalog number (Example: T40N WH).

TRAC-MASTER®

Avant Garde

WIREFORM® SERIES**T430, T431, T433, T435 and T437****Line Voltage PAR30****Socket** Medium base porcelain with nickel plated copper screw shell.**Adapters** Refer to **T431**.

Catalog Number	Description	Finish	Lamp
T435 WH	Wireform w/Universal Trac Adapter	White	75W PAR30 max.
T435 BL	Wireform w/Universal Trac Adapter	Black	75W PAR30 max.
T435 SC	Wireform w/Universal Trac Adapter	Satin Chrome	75W PAR30 max.
T435 SL	Wireform w/Universal Trac Adapter	Silver	75W PAR30 max.
T435 TEK WH	Wireform w/TEK Trac Adapter	White	75W PAR30 max.
T435 TEK BL	Wireform w/TEK Trac Adapter	Black	75W PAR30 max.
T435 TEK SC	Wireform w/TEK Trac Adapter	Satin Chrome	75W PAR30 max.
T435 TEK SL	Wireform w/TEK Trac Adapter	Silver	75W PAR30 max.
T435 GTYPE WH	Wireform w/G-Type Trac Adapter	White	75W PAR30 max.
T435 GTYPE BL	Wireform w/G-Type Trac Adapter	Black	75W PAR30 max.
T435 GTYPE SC	Wireform w/G-Type Trac Adapter	Satin Chrome	75W PAR30 max.
T435 GTYPE SL	Wireform w/G-Type Trac Adapter	Silver	75W PAR30 max.
T435 HTYPE WH	Wireform w/H-Type Trac Adapter	White	75W PAR30 max.
T435 HTYPE BL	Wireform w/H-Type Trac Adapter	Black	75W PAR30 max.
T435 HTYPE SC	Wireform w/H-Type Trac Adapter	Satin Chrome	75W PAR30 max.
T435 HTYPE SL	Wireform w/H-Type Trac Adapter	Silver	75W PAR30 max.
T435 LTYPE WH	Wireform w/L-Type Trac Adapter	White	75W PAR30 max.
T435 LTYPE BL	Wireform w/L-Type Trac Adapter	Black	75W PAR30 max.
T435 LTYPE SC	Wireform w/L-Type Trac Adapter	Satin Chrome	75W PAR30 max.
T435 LTYPE SL	Wireform w/L-Type Trac Adapter	Silver	75W PAR30 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description
HCLBL 375	Hexcell Louver - Black	UVF 375	UV Filter
CCLBL 375	Cube Cell Louver - Black	SOLITE 375	Uniformity Lens (Solite)
SNOOTBL 375	Snoot - Black	PRISM 375	Prismatic Spread Glass Lens
CGF 375	Color Glass Filter	LSPREAD 375	Linear Spread Glass Lens
DCCF 375	Dichroic Color Correction Filter	TW75BL	Barn Doors - Black †
DGF 375	Dichroic Glass Filter	T40N¹	Monopoint
DIFF 375	Diffusion Glass Lens		

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Filters, lenses, snoot and louver require barn doors for installation.

Notes:

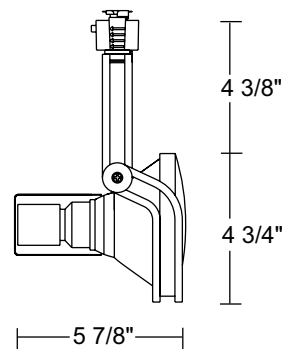
1 Add finish code to complete catalog number (Example: T40N WH).

TRAC-MASTER®

Avant Garde

WIREFORM® SERIES**T430, T431, T433, T435 and T437****Line Voltage PAR38****Socket** Medium base porcelain with nickel plated copper screw shell.**Adapter** Refer to **T431**.

Catalog Number	Description	Finish	Lamp
T437 WH	Wireform w/Universal Trac Adapter	White	150W PAR38 max.
T437 BL	Wireform w/Universal Trac Adapter	Black	150W PAR38 max.
T437 SL	Wireform w/Universal Trac Adapter	Silver	150W PAR38 max.
T437 TEK WH	Wireform w/TEK Trac Adapter	White	150W PAR38 max.
T437 TEK BL	Wireform w/TEK Trac Adapter	Black	150W PAR38 max.
T437 TEK SL	Wireform w/TEK Trac Adapter	Silver	150W PAR38 max.
T437 GTYPE WH	Wireform w/G-Type Trac Adapter	White	150W PAR38 max.
T437 GTYPE BL	Wireform w/G-Type Trac Adapter	Black	150W PAR38 max.
T437 GTYPE SL	Wireform w/G-Type Trac Adapter	Silver	150W PAR38 max.
T437 HTYPE WH	Wireform w/H-Type Trac Adapter	White	150W PAR38 max.
T437 HTYPE BL	Wireform w/H-Type Trac Adapter	Black	150W PAR38 max.
T437 HTYPE SL	Wireform w/H-Type Trac Adapter	Silver	150W PAR38 max.
T437 LTYPE WH	Wireform w/L-Type Trac Adapter	White	150W PAR38 max.
T437 LTYPE BL	Wireform w/L-Type Trac Adapter	Black	150W PAR38 max.
T437 LTYPE SL	Wireform w/L-Type Trac Adapter	Silver	150W PAR38 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description
HCLBL 469	Hexcell Louver - Black	UVF 469	UV Filter
CCLBL 469	Cube Cell Louver - Black	SOLITE 469	Uniformity Lens (Solite)
SNOOTBL 469	Snoot - Black	PRISM 469	Prismatic Spread Glass Lens
CGF 469	Color Glass Filter	LSPREAD 469	Linear Spread Glass Lens
DCCF 469	Dichroic Color Correction Filter	TW72BL	Barn Doors - Black †
DGF 469	Dichroic Glass Filter	T40N¹	Monopoint
DIFF 469	Diffusion Glass Lens		

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Filters, lenses, snoot and louver require barn doors for installation.

Notes:

1 Add finish code to complete catalog number (Example: T40N WH).