



# TRAC-MASTER®

Avant Garde

## DELTA 200 SERIES

T216, TP216, T218 and T219

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

### PRODUCT DESCRIPTION

The Delta 200 Series attains the ultimate caliber of clean lines in today's popular open fixture look. The die-cast aluminum exterior features the detailed styling of a precision lighting instrument with a sleek vented look.


**Construction** Die-cast aluminum body.

**Aiming** 90° vertical aiming capability and 358° rotation

- One locking screw provided.

**Labels** UL listed, CSA certified.

Product specifications subject to change without notice.

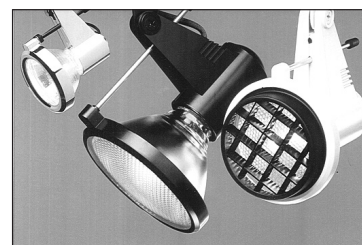

### Low Voltage MR16

**Socket** Ceramic bi-pin.

**Transformer** Must be ordered separately • Compatible with T537 or T538 12V electronic transformer for halogen lamps (D1.2.1) • Compatible with T537U universal 12V electronic transformer for LED or halogen lamps (D1.2.5) • Compatible with T539 12V electronic transformer for halogen lamps (D1.2.0) • Compatible with T542 or T543 12V magnetic transformer for LED or halogen lamps (D1.2.0).


Catalog Number	Finish	Lamp
T216WH	White	50W MR16 max.
T216BL	Black	50W MR16 max.
T216SL	Silver	50W MR16 max.

### ACCESSORIES


Cat. No.	Description	Cat. No.	Description	Cat. No.	Description
T74BL	Black Barn Doors	T557	Prismatic Spread Lens	T559	Linear Spread Lens
T551-5	Color Filters	T558BL	Black Snoot	T5501-18	Dichroic Filters
T5520	Diffusion Lens	T5521	Uniformity Lens	T5522	UV Filter

T5559BL Hexcell Louver


See specification sheet D1.2.2 for details.

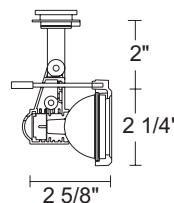

T537, T537U

 

T538

 

### Low Voltage MR16

**Socket** Ceramic bi-pin.

**Transformer** Must be ordered separately • Compatible with T537 or T538 12V electronic transformer for halogen lamps (D1.2.1) • Compatible with T537U universal 12V electronic transformer for LED or halogen lamps (D1.2.5) • Compatible with T539 12V electronic transformer for halogen lamps (D1.2.0) • Compatible with T542 or T543 12V magnetic transformer for LED or halogen lamps (D1.2.0).


Catalog Number	Description	Finish	Lamp
TP216WH	Delta 200 Pendant	White	50W MR16 max.
TP216BL	Delta 200 Pendant	Black	50W MR16 max.
TP216SL	Delta 200 Pendant	Silver	50W MR16 max.

### ACCESSORIES


Cat. No.	Description	Cat. No.	Description	Cat. No.	Description
T74BL	Black Barn Doors	T557	Prismatic Spread Lens	T559	Linear Spread Lens
T551-5	Color Filters	T558BL	Black Snoot	T5501-18	Dichroic Filters
T5520	Diffusion Lens	T5521	Uniformity Lens	T5522	UV Filter

T5559BL Hexcell Louver


See specification sheet D1.2.2 for details.

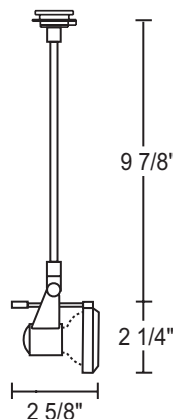

T537, T537U

 

T538

 

**TRAC-MASTER®**

Avant Garde

**DELTA 200 SERIES****T216, TP216, T218 and T219****PRODUCT DESCRIPTION**

The Delta 200 Series attains the ultimate caliber of clean lines in today's popular open fixture look. The die-cast aluminum exterior features the detailed styling of a precision lighting instrument with a sleek vented look.

**Construction** Die-cast aluminum body.

**Aiming** 90° vertical aiming capability and 358° rotation

- One locking screw provided.

**Adapter** Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included

- Patented embossed polarity arrows on bottom of adapter
- Spring-loaded positive latch with embossed polarity arrows secures trac light to trac
- "Pull-up" contact to up position for two-circuit application.

**Labels** UL listed, CSA certified.

Product specifications subject to change without notice.

**Line Voltage PAR30**


**Socket** Medium base porcelain with nickel plated copper screw shell.

Catalog Number	Finish	Lamp
<b>T218WH</b>	White	75W PAR30 max.
<b>T218BL</b>	Black	75W PAR30 max.
<b>T218SL</b>	Silver	75W PAR30 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description	Cat. No.	Description
<b>T569BL</b>	Cube Cell Louver	<b>T577BL</b>	Black Eyebrow	<b>T660BL</b>	Black Filter Holder
<b>T561-6</b>	Color Filters	<b>T5677</b>	Prismatic Spread Lens	<b>T5678</b>	Linear Spread Lens
<b>T5621</b>	Uniformity Lens	<b>T5622</b>	UV Filter	<b>T5618</b>	Color Correction Filter

See specification sheet [D1.2.2](#) for details.

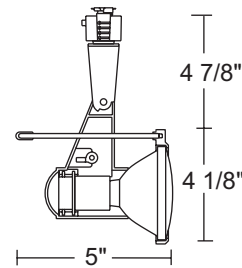**Line Voltage PAR38**


**Socket** Medium base porcelain with nickel plated copper screw shell.

Catalog Number	Finish	Lamp
<b>T219WH</b>	White	150W PAR38 max.
<b>T219BL</b>	Black	150W PAR38 max.
<b>T219SL</b>	Silver	150W PAR38 max.

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description	Cat. No.	Description
<b>T579BL</b>	Cube Cell Louver	<b>T587BL</b>	Black Eyebrow	<b>T571-6</b>	Color Filters
<b>T670BL</b>	Black Filter Holder	<b>T5777</b>	Prismatic Spread Lens	<b>T5778</b>	Linear Spread Lens
<b>T5721</b>	Uniformity Lens	<b>T5722</b>	UV Filter	<b>T5718</b>	Color Correction Filter

See specification sheet [D1.2.2](#) for details.

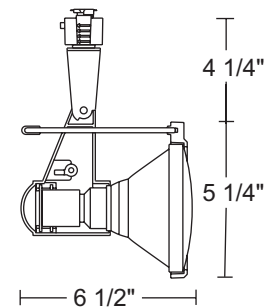

1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925  
 220 Chrysler Drive • Brampton, Ontario • Canada L6S 6B6 • Phone (905) 792-7335 • Fax (905) 792-0064  
 Visit us at [www.junolightinggroup.com](http://www.junolightinggroup.com)

Printed in U.S.A. ©2014 Juno Lighting, LLC.