

LED accent lights


LED accent lighting

Product description


LNL1, LNL3, LNL4

LED accent lights features & benefits

- Fits into a standard junction box for easy installation (single-gang, handy box, 2" minimum inside width)
- Delivers up to 30 lumens of illumination
- Energy-efficient LED light source
- Ship with 4 color lenses that are quickly and easily field-installable
- Illumination colors include white (4000k), amber, red and blue
- Lenses are 0.040" thick polycarbonate, and are quickly and easily field-installable
- Wet location listed (LNL3 series wet location listed about 4' mounting height)
- Die-cast aluminum face plates available in white, black and brushed nickel

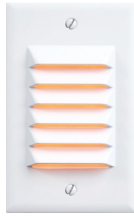

LNL1 series

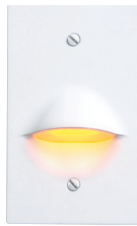

LNL3 series



LNL4 series

LED nightlights with vertical louvered faceplate

Rating V/AC	Description	Color suffix	Catalog no.
120-277	LED accent light, vertical louvered plate	B, BN, W	□ LNL1__-UNV
120	LED accent light, scoop plate	B, BN, W	□ LNL3__-UNV
120-277	LED accent light, horizontal louvered plate	B, BN, W	□ LNL4__-UNV

LED combination nightlights

Product description

Single-pole
1W 120V/AC, back & side wire

Combination LED wallbox nightlight & switch

Rating A	Rating V/AC	Description	Color suffix	Catalog no.
15	120	Single-pole switch with nightlight	A, BK, LA, V, W	□ 7738__
		Full nightlight	A, BK, LA, V, W	□ 7737__



7738



7737

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Black), BN (Brushed Nickel), LA (Light Almond), V (Ivory), W (White)

A	B/BK	BN	LA	V	W
(Almond)	(Black)	(Brushed Nickel)	(Lt. Almond)	(Ivory)	(White)

Material characteristics: Faceplate, die-cast aluminum. Back body, ABS plastic. Strap, aluminum. Wire, 18 AWG, 600V, 105°V. Temperature rating: 25°C (77°F) **Specification information:** J-23

Compliances, specifications and availability are subject to change without notice.