


Home > Electrical > Lighting > 150W String Light

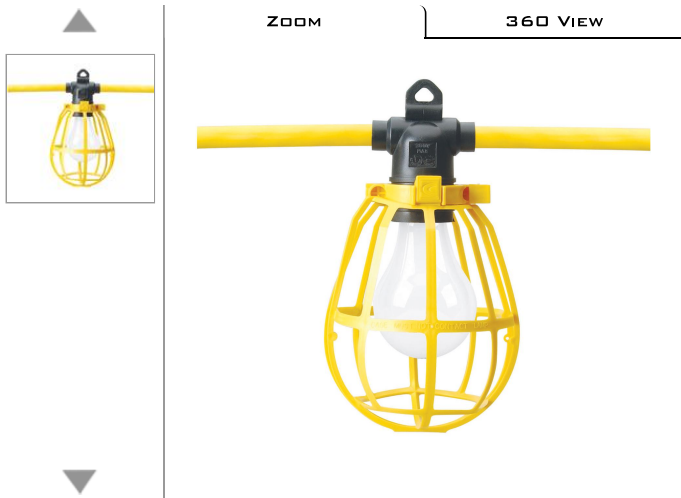

150W String Light

★★★★★ [Write a review](#) [Ask a question](#)

7548SW

7548SW Temporary Lighting, 50-Foot Cord with 5 Light Sockets and Plastic Lamp Guards, 3-Prong Plugs (5-15P). Durable, indoor/outdoor lighting systems accommodate Standard (A-23) bulbs up to 150 Watts. They Feature a lamp socket every 10 feet. This lighting system is our most rugged and heavy-duty. It features a 12/3 AWG cord. It is made in yellow for high visibility and rated to 300 volts. The Plug is rated to 15 Amps, and is the standard shape (5-15R). It also has an outlet (receptacle) on the end to interconnect more than one set. The plastic lamp guards snap on easily. These have many uses: For concerts, parties, outdoor events, construction lighting and commercial lighting. Many people call them string lights.

Add To Wishlist

Register

FEATURES

SPECIFICATIONS

DOWNLOADS

FEATURES

- Perfect for construction sites
- Plugs into a standard 3 prong outlet
- Super heavy duty wire will outlast

INCLUDES

Featured Products



ES001
ELECTRICIAN'S SCISSORS



THEX6-1/2
1/2" T-HANDLE HEX KEY

Reviews



[Be the first to review this product](#)

Questions

[Ask a question](#)

1-2 of 2 Questions

Sort by: Newest answers ▼

Safteybear · 4 months ago

1