

60W

ROTATABLE LUMINAIRE



Ideal for security lighting, wall washing, flood lighting, and more
Use as a flood light - uplight, downlight, or both!

2 Independent Rotatable Modules
to offer flexible light control

Oversized Heat Sink
for superior thermal management



Heavy Die Cast
Aluminum

LM80 tested
CREE chips

Superior anodized
paint finish

TECHNICAL DATA




LIGHT SPECIFICATIONS

Lumens	7,809 lm
Efficacy	128.46 lm/W
CCT	4000K
Beam angle	60°
CRI	73.8
Dimmable	No
Rated hours	50,000
Warranty	10-year

APPROVALS AND LISTINGS

cUL	E482965
DLC PREMIUM	PLUFD2DWXNQ6

DIMENSIONS

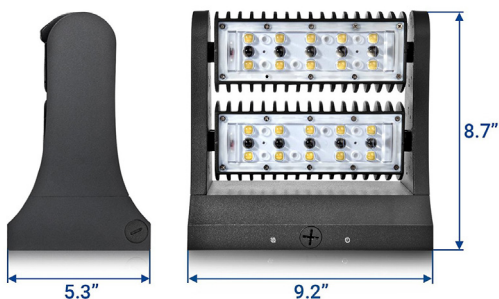

MAKE THE SMART CHOICE.
COMPARE LUMENS PER WATT
128+ LM/W

ELECTRICAL

Wattage	60W
Voltage	100-277V
Power factor	0.9
THD	12.31%
Operating temp	-30° to 45° C

CONSTRUCTION

Housing	Cast aluminum
Finish	Anodized finish
Colour	Bronze
IP rating	IP65
Weight	6.68 lbs
Carton qty	2

ILLUMINANCE CONE

