



# 2-010

## Round Insulated Airtight MR16

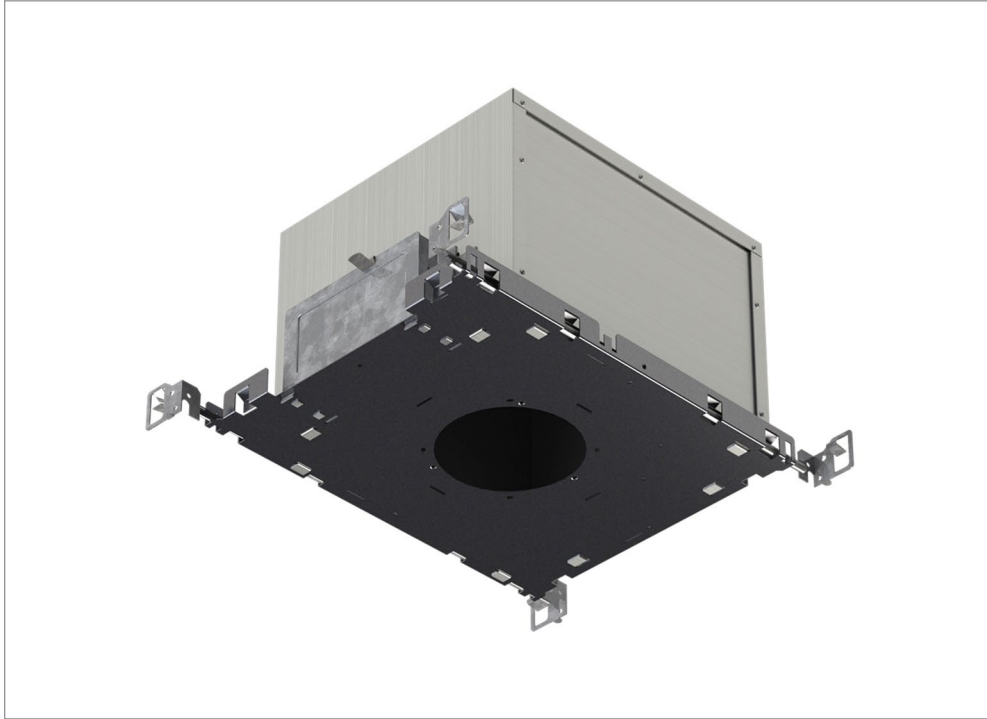

4"  
Insulated  
Housing

MR16 Halogen

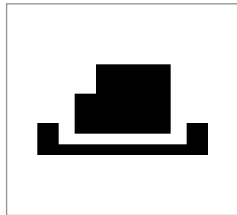

The 2-010 series housing is designed for insulated and airtight ceilings. Performing in accordance with ASTM E283-91, the airtight option also meets the requirements of "having no more than 2.0 CFM air movement from the conditioned space to the ceiling cavity" (Sec. 502.4 of 1991 WSEC- Washington State electrical code).

- Low voltage (12V) MR16 lamp (sold separately)
- Porcelain Bi Pin socket type GX5.3
- MR16 LED lamp is compatible with E15 electronic transformer option
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Approved for branch circuit wiring
- Transformer accessible through the ceiling




2-010-MR16-Specs • Subject to change without notice • Rev 2016.05.25 • 1/5



# Housing Types
 
## INSULATED & AIRTIGHT

Ceiling Cutout




Dimensions

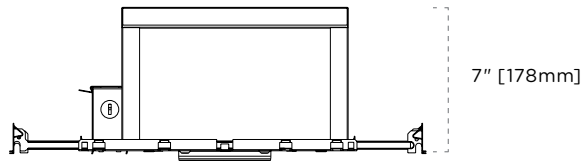
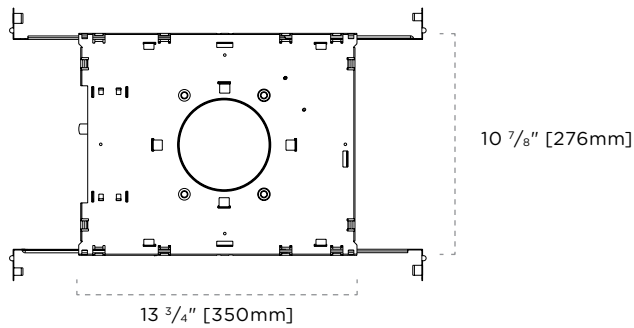


## TRIMLESS INSULATED & AIRTIGHT

 Ceiling Cutout





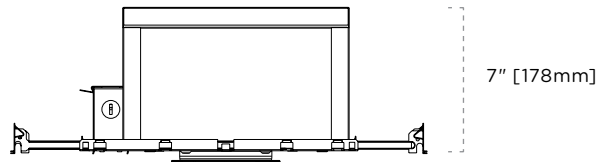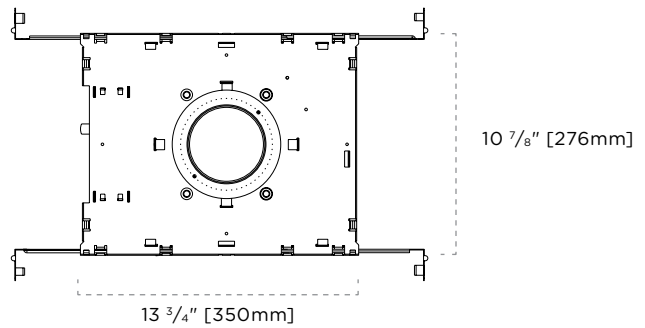










 









Dimensions



## MAXIMUM WATTAGES

 
TRANSFORMER TYPE	INPUT VOLTAGE			NOTES
	120V	277V	347V	
MAGNETIC	50W	50W	50W	Made of copper windings with a class H rating (180°C)
ELECTRONIC	37W	37W	—	
E-15 ELECTRONIC	15W	15W	—	Only compatible with Sora MR16 LED
Q-TRAN	50W	50W	—	Toroidal magnetic silent transformer
MAGNETIC POTTED	50W	—	—	Epoxy encapsulated

# Compatible Trims

 
Trim	Trim Type	
	Trimmed	Trimless
2-110 Coral		—
2-112 Round Wall Wash		—
2-115 Aqua		
2-120 Aurora		
2-125 Deep Aurora		
2-130 Sunburst		—
2-140 Eclipse		—
2-150 Siris		—
2-160 Demi		—
2-167 Starlite		
2-170 Conus		
2-175 Corona		—
2-180 Pinhole		
2-182 Flare Wall Wash		
2-185 Piccolo		

2-010-MR16-Specs • Subject to change without notice • Rev 2016.05.25 • 3/5

2-187  
Lensed Picolo




2-190  
Keyhole

 

2-195  
Pivot



 2-197  
Linover



2-200  
Split



# 2-010 MR16

Project

Type

Notes

Housing Code

\_\_\_\_\_

1            2            3            4            5

## 1. Housing Type

**2-010** Round Insulated Airtight

## 2. Trim Type

**IC** Insulated

**IC-AT** Insulated Airtight

**IC-TL** Trimless Insulated

**IC-AT-TL** Trimless Airtight Insulated

## 3. Transformer

**MT** Magnetic

**E** Electronic

**E15** 15W Electronic <sup>1</sup>

**TOR** Q-Tran Toroidal Magnetic

**MPT** Magnetic Potted <sup>2</sup>

## 4. Voltage

**120**

**277**

**347**

## 5. Options

**BPHI** Black Painted Housing interior

**WPHI** White Painted Housing Interior

Notes

<sup>1</sup> **E15** transformer option is only compatible with Soraa MR16 LED lamp.

<sup>2</sup> **MPT** transformer option is available in 120V.