




17-03

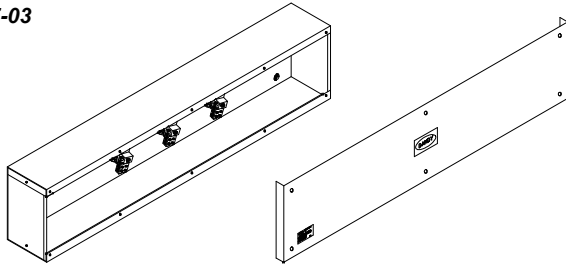

Model #DS3R-3-225-48 Shown

3 WIRE SPLITTER TROUGH

EEMAC 3R

MODEL #DS3R-3

- EEMAC 3R enclosure
- Suitable for indoor or outdoor use
- Galvanized steel construction - ASA 61 grey cover
- 3 Pole 600V rated lugs provided
- Lugs Al/Cu rated - no knockouts
- Punch raised rear mounting dimples

Options

- EEMAC 4 or 4X

| Model # | Dimensions H x W x D (") | Rating | Lug Ratings AWG | | Weight (lbs) |
|---------------|-----------------------------|------------|--------------------------|------------|--------------|
| | | | Mains | Secondary | |
| DS3R-3-125-24 | 8 x 24 x 5 | 125A, 600V | (1) 1/0-14 | (6) 2-14 | 16.2 |
| DS3R-3-125-36 | 8 x 36 x 5 | 125A, 600V | (1) 1/0-14 | (6) 2-14 | 22.9 |
| DS3R-3-125-48 | 8 x 46 x 5 | 125A, 600V | (1) 1/0-14 | (6) 2-14 | 29.6 |
| DS3R-3-225-24 | 9 x 24 x 6 | 225A, 600V | (1) 300-6 | (6) 2/0-14 | 18.8 |
| DS3R-3-225-36 | 9 x 36 x 6 | 225A, 600V | (1) 300-6 | (6) 2/0-14 | 27.6 |
| DS3R-3-225-48 | 9 x 46 x 6 | 225A, 600V | (1) 300-6 | (6) 2/0-14 | 35.3 |
| DS3R-3-225-60 | 9 x 58 x 6 | 225A, 600V | (1) 300-6 | (6) 2/0-14 | 43.1 |
| DS3R-3-225-72 | 9 x 70 x 6 | 225A, 600V | (1) 300-6 | (6) 2/0-14 | 51.4 |
| DS3R-3-400-36 | 10 x 36 x 6 | 400A, 600V | (1) 600-4 or (2) 250-1/0 | (6) 3/0-14 | 30.4 |
| DS3R-3-400-48 | 10 x 46 x 6 | 400A, 600V | (1) 600-4 or (2) 250-1/0 | (6) 3/0-14 | 38.7 |
| DS3R-3-400-60 | 10 x 58 x 6 | 400A, 600V | (1) 600-4 or (2) 250-1/0 | (6) 3/0-14 | 46.9 |
| DS3R-3-400-72 | 10 x 70 x 6 | 400A, 600V | (1) 600-4 or (2) 250-1/0 | (6) 3/0-14 | 55.2 |
| DS3R-3-600-48 | 12 x 46 x 7 | 600A, 600V | (2) 600-4 or (4) 250-1/0 | (6) 3/0-14 | 46.9 |
| DS3R-3-600-60 | 12 x 58 x 7 | 600A, 600V | (2) 600-4 or (4) 250-1/0 | (6) 3/0-14 | 78.8 |
| DS3R-3-600-72 | 12 x 70 x 7 | 600A, 600V | (2) 600-4 or (4) 250-1/0 | (6) 3/0-14 | 92.7 |