

## SL7.5 - Indoor Diffusion LED Strip

### Description

Diffusion LED Strip SL7.5 is a flexible 10mm wide linear LED strip. It is available in lengths up to 32' and can be cut every 6 LED chips (25mm/1").

\*Note: SL7.5 needs to be installed in aluminum channel\*

### Features

- 3M industrial strength adhesive tape (included)
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 24" leads on both ends of each roll

\*Custom lengths recommended\*


### Specifications

- LED : 16.4 W/m (5W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 266/m (80/ft)
- Power Input : 24V DC
- CRI > 95
- R values all over 95


### Lumens

- 2700K = 1576 lm/m (472 lm/ft) ●
- 3000K = 1680 lm/m (504 lm/ft) ●
- 3400K = 1800 lm/m (540 lm/ft) ●
- 4100K = 1936 lm/m (580 lm/ft) ○

\*Custom Kelvins available upon request\*

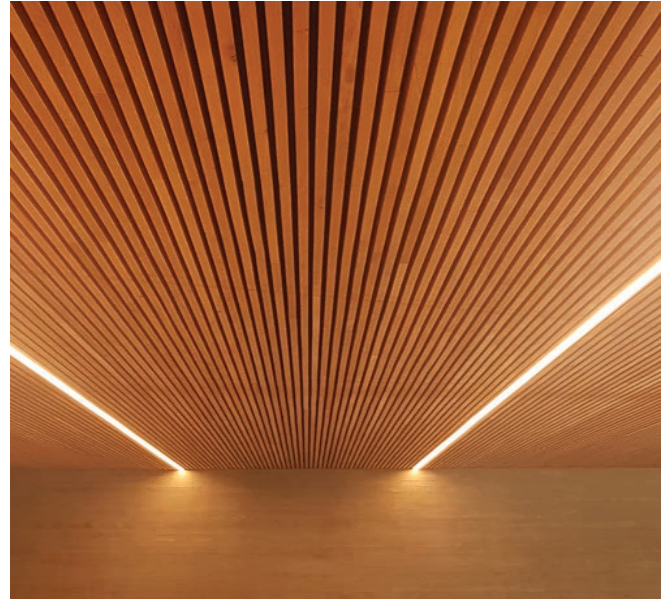

\*Recommended ordering in custom cut\*  
\*No connectors for SL7 series\*

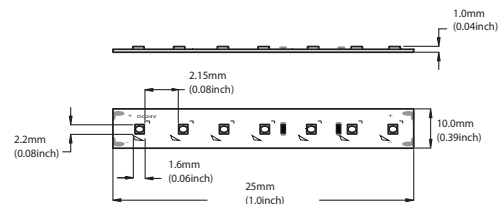

ORDERING  
CODE

SL7.5-IN

LENGTH

xx

VOLTAGE

24V

KELVIN

xxxx

SL7.5-IN

16 ft

24 Volt

2700 K

3000 K

3400 K

4100 K

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

