

SL1 - Outdoor Diffusion LED Strip

Description

Diffusion SL-1 is a flexible 10mm wide linear LED strip. It is available in 16' and 32' rolls that can be cut every 6 LEDs (100mm or 4").

Features





- Includes endcaps and mounting clips with screws
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 2' power feeds on both ends of every roll
- IP67

Custom lengths available upon request


Specifications

- LED : 4.8 W/m (1.5W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 60/m (18/ft)
- Power Input : 24V DC
- CRI > 91

Lumens

- 2700K = 394 lm/m (120 lm/ft) 
- 3000K = 416 lm/m (126 lm/ft) 
- 3400K = 438 lm/m (132 lm/ft) 
- 4100K = 460 lm/m (140 lm/ft) 

Custom Kelvins available upon request

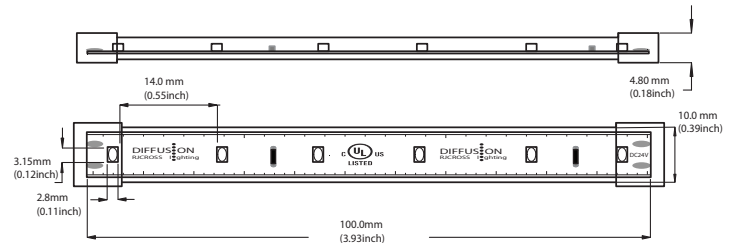

ORDERING
CODE

LENGTH

VOLTAGE

KELVIN



SL1-OUT
16 ft
32 ft

24 Volt

2700 K
3000 K
3400 K
4100 K

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

